

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [45560-0160](#)  
**Status:** **Active**  
**Overview:** HandyLink™ I/O Interconnect System  
**Description:** 0.80mm Pitch HandyLink™ Perpendicular Surface Mount Cradle Connector Assembly, 16 Circuit

**Documents:**

[3D Model](#) [Product Specification PS-44828-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family I/O Connectors  
 Series [45560](#)  
 Application Board-to-Board  
 Comments Perpendicular-PCB  
 Component Type Plug  
 MolexKits Yes  
 More Detailed Tech Information [handylink@molex.com](mailto:handylink@molex.com)  
 Overview [HandyLink™ I/O Interconnect System](#)  
 Product Name HandyLink®  
 Type N/A  
 UPC 822348066131


**Physical**

Circuits (Loaded) 16  
 Circuits (maximum) 16  
 Flammability 94V-0  
 Lock to Mating Part Yes  
 Material - Metal Phosphor Bronze  
 Material - Plating Mating Gold  
 Material - Plating Termination Tin  
 Net Weight 2.246/g  
 Orientation Vertical  
 PCB Locator No  
 PCB Retention Yes  
 PCB Thickness - Recommended 1.50mm  
 Packaging Type Embossed Tape on Reel  
 Panel Mount No  
 Pitch - Mating Interface 0.80mm  
 Plating min - Mating 0.051µm  
 Plating min - Termination 3.810µm  
 Polarized to Mating Part Yes  
 Surface Mount Compatible (SMC) N/A  
 Temperature Range - Operating -40°C to +85°C  
 Termination Interface: Style Surface Mount  
 Wire Size AWG N/A

**Electrical**

Current - Maximum per Contact 1.5A  
 Shielded No  
 Voltage - Maximum 30V

**Solder Process Data**

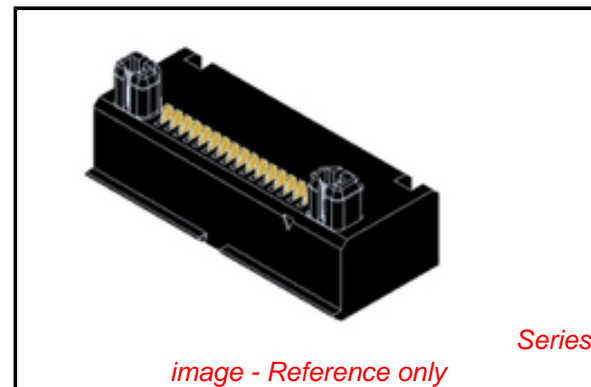

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC Contains SVHC: No**  
**Low-Halogen Status Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[45560Series](#)

**Mates With**

[44828](#)

Duration at Max. Process Temperature (seconds)	3
Lead-free Process Capability	Reflow Capable (SMT only)
Max. Cycles at Max. Process Temperature	1
Process Temperature max. C	260

### **Material Info**

### **Reference - Drawing Numbers**

Product Specification	PS-44828-001
Sales Drawing	SD-45560-001

This document was generated on 03/02/2015

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**