




Datasheet

New 3.81 mm Plug with Flange 8A 6 Way

RS Stock 874-5130



Dimensions: (mm)

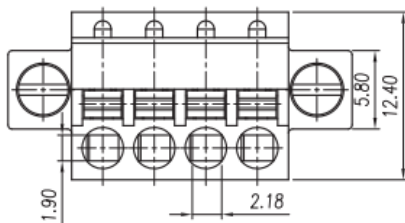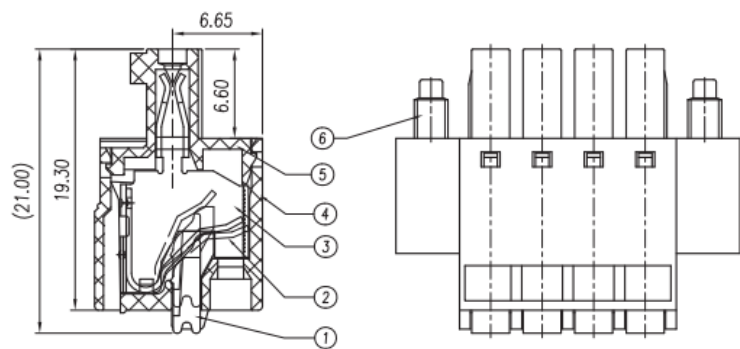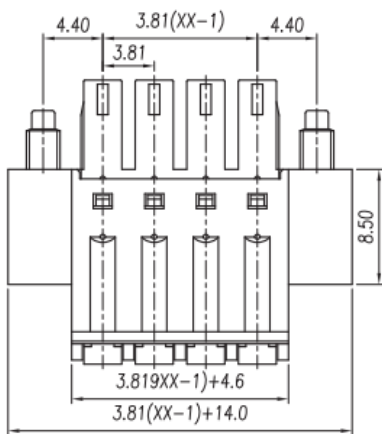



ENGLISH

Specifications

Mechanical

Steip Length 7-8mm
Temp.Range -40°C~+105°C
Torque 0.4Nm(3.6Lb.in)

Dimensions

Pitch 3.81mm
Poles 2~24p

Material

Housing PA66, UL94V-0
Screws M2.5 Steel, Zn plated
Clamp Phosphor bronze, Ni plated
Wire guard Stainless steel

Standard	UL	IEC
Rated voltage	300V	250V
Rated current	8A	13.5A
Contact resistance	20mΩ	
Insulation resistance	500MΩ/DC500V	
Wire range	28~16AWG	1mm ²
Wrth standing voltage	AC 2000V/1 Min	