



SL-156

TE Internal #: 1-770996-5

Housing, Receptacle, Wire-to-Board, 15 Position, 3.96 mm [.156 in]

Centerline, Crimp, 1 Row, Natural, Wire & Cable, Power & Signal,

SL-156

[View on TE.com >](#)

Connectors > PCB Connectors > Wire-to-Board Connectors > Wire-to-Board Connector Assemblies & Housings



Connector Product Type: **Housing**

Connector & Housing Type: **Receptacle**

Connector System: **Wire-to-Board**

Number of Positions: **15**

Centerline (Pitch): **3.96 mm [.156 in]**

Features

Product Type Features

Connector Product Type	Housing
Connector & Housing Type	Receptacle
Connector System	Wire-to-Board
Sealable	No
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	15
Number of Rows	1

Electrical Characteristics

Operating Voltage	250 VAC
-------------------	---------

Body Features

Primary Product Color	Natural
-----------------------	---------

Contact Features

--	--



Contact Layout	Inline
Contact Retention Within Housing	Without
Contact Type	Socket

Termination Features

Termination Method to Wire & Cable	Crimp
------------------------------------	-------

Mechanical Attachment

Strain Relief	Without
Panel Mount Feature	Without
PCB Mount Alignment	Without
PCB Mount Retention	Without
Mating Retention	Without
Connector Mounting Type	Cable Mount (Free-Hanging)

Housing Features

Housing Material	Nylon - GF
Centerline (Pitch)	3.96 mm[.156 in]

Dimensions

	2.34 in
--	---------

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Power & Signal
---------------------	----------------

Industry Standards

Compatible With Agency/Standards Products	CSA, UL
UL Flammability Rating	UL 94V-0

Packaging Features

Packaging Method	Package
Packaging Quantity	1

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant








China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

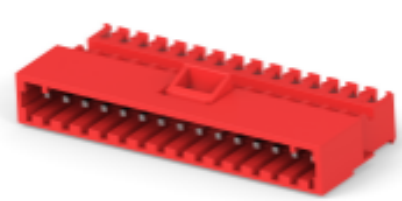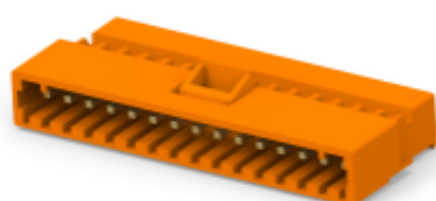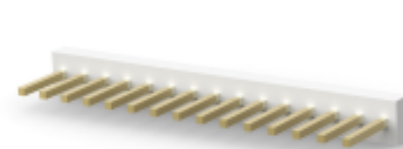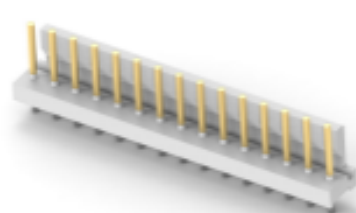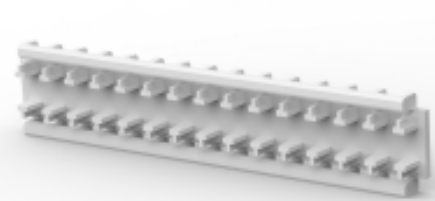 TE Part # 4-641524-5 15P MTA156 POST CON ASSY LF	 TE Part # 4-644807-5 15P MTA156 PSTD CONN 18AWG LF	 TE Part # 4-641438-5 15P MTA156 PSTD CONN ASSY WHT	 TE Part # 4-641202-5 15P MTA156 HDR ASSY PL 30AU LF
 TE Part # 4-641209-5 15P MTA156 HDR ASSY FL ST LF	 TE Part # 1-640551-5 15P MTA156 COVER	 TE Part # 1-640643-5 15P MTA156 COVER F/T	 TE Part # 1-643071-5 15P 156 CL MTA FD/TH COVER



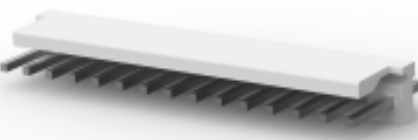

TE Part # 1-644752-5
15P MTA156 HDR ASSY SQ STR F/L

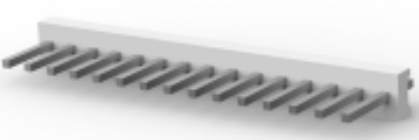


TE Part # 1-640383-5
15P MTA156 HDR ASSY STR SQ SN



TE Part # 1-640445-5
15P MTA156 HDR ASSY FL/STR SNL




TE Part # 1-640387-5
15P MTA156 HDR ASSY SQ R/A

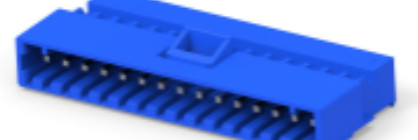


TE Part # 4-641439-5
15P MTA156 PST CON ASSY LF



TE Part # 1-644751-5
15P MTA156 HDR ASSY R/A

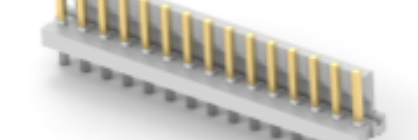


TE Part # 4-644766-5
15P MTA156 HDR ASSY STR SQ LF

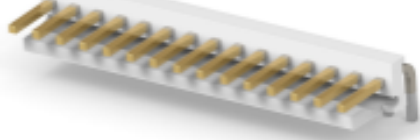


TE Part # 4-644769-5
15P MTA156 HDR ASSY R/A SQ LF




TE Part # 4-641120-5
15P MTA156 HDR ASSY FL/ST LF

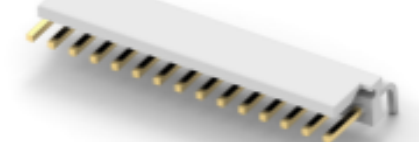

TE Part # 4-641210-5
15P MTA156 HDR FLRA FB 30AU LF

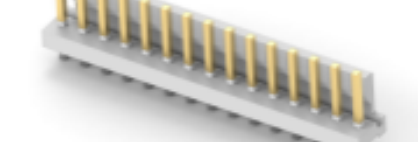

TE Part # 4-641208-5
15P MTA156 HDR ASSY FL ST LF

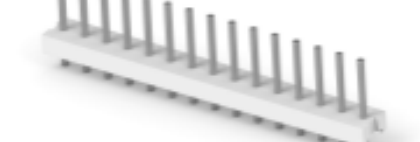

TE Part # 1-640384-5
15P MTA156 HDR ASSY STR RND SN

Also in the Series | SL-156



Connector Contacts(23)



Connector Hardware(4)



Power Contacts(13)



Rectangular Connector Housings(139)



Rectangular Power Connectors(139)



Standard Rectangular Connectors(139)



Wire-to-Board Connector Assemblies & Housings(11)

Customers Also Bought



TE Part #3-640440-3
03P MTA100 CONN ASSY 22AWG RED



 
TE Part #36201
TERMINAL,BUDG R 16-14HD 3/4



TE Part #1375820-8
CST-100 II HOUSING 8 POS



TE Part #52957-1
TERMINAL,PG SPR SPD 16-14 10



TE Part #324001
SPLICE,SOLIS BUTT STRAP 24-20



TE Part #1-1600616-9
MBXL HOUSING W/GUIDES RCPT CBL PANEL MOU



TE Part #CN9931-000
SBP190594WE1



TE Part #52856-1
TERMINAL,PG SPD FLG 12-10 10



TE Part #1-480305-0
03P CMNL CAP HSG F/H NATL



TE Part #1-465184-0
LUBRICATOR ASSEMBLY

Documents

Product Drawings

15P SL 156 HSG W/TABS W/O LR

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-770996-5_J_c-1-770996-5-j.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-770996-5_J_c-1-770996-5-j.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-770996-5_J_c-1-770996-5-j.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications



Application Specification

Japanese

Application Specification

English

MTA 156 Ribbon Cable Connector Assemblies (English And Spanish)

English

MTA 156 Ribbon Cable Connector Assemblies (English And Spanish)

Japanese

Application Specification

English

Agency Approvals

UL Report

English