

HC-D 15-AP-GY - Cover plate



1660342

<https://www.phoenixcontact.com/in/products/1660342>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

HEAVYCON cover plate, for wall cutouts of type D15, 3.5 mm thick, gray



Commercial data

Item number	1660342
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF7
Product key	AF7AZD
Catalog page	Page 664 (C-2-2019)
GTIN	4017918021986
Weight per piece (including packing)	11.75 g
Weight per piece (excluding packing)	11.34 g
Customs tariff number	39269097
Country of origin	DE

HC-D 15-AP-GY - Cover plate

1660342

<https://www.phoenixcontact.com/in/products/1660342>



Technical data


Notes

General	For wall cutouts of type D15
---------	------------------------------

Product properties

Product type	Cover plate
Type	D15
Seal present	yes

Dimensions

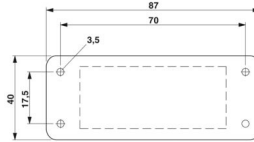Dimensional drawing	
Width	40 mm
Height	3.5 mm
Length	87 mm
Drill hole distance, horizontal	70 mm
Drill hole distance, vertical	17.5 mm
Hole diameter	3.5 mm

Installation dimensions

Width of the assembly cutout	24 mm
Length of the assembly cutout	58 mm

Material specifications

Material	PA
Flammability rating according to UL 94	HB
Seal material	PTS

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-20 °C ... 100 °C


HC-D 15-AP-GY - Cover plate

1660342

<https://www.phoenixcontact.com/in/products/1660342>



Drawings

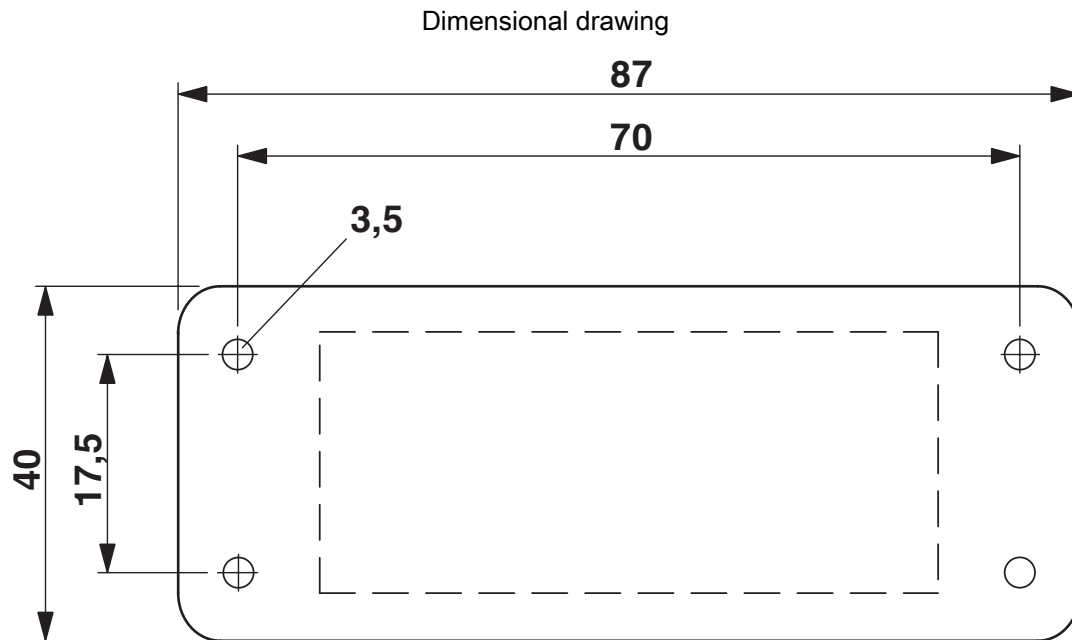

Dimensional drawing

HC-D 15-AP-GY - Cover plate



1660342

<https://www.phoenixcontact.com/in/products/1660342>

Classifications

ECLASS

ECLASS-11.0	27440201
ECLASS-12.0	27440201
ECLASS-13.0	27440201

ETIM

ETIM 9.0	EC002309
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

HC-D 15-AP-GY - Cover plate



1660342

<https://www.phoenixcontact.com/in/products/1660342>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in