

Electromagnetic ballasts



Type: LN58.742 230V/50HZ

Item number: 169784


Standard version

Vacuum-impregnated with polyester resin



Lamp type:	T12
Output [W]:	0065
Voltage [V]:	230
Shape [mm*mm]:	28x41
Stack length [mm]:	124
Fixing centre [mm]:	220
Overall length [mm]:	235
Protection from overheating:	Without thermal cut-out
Encapsulated:	No
Delta t Max. [K]:	45
Connection:	Push-in terminal
Earth terminal:	No
Frequency [Hz]:	50
Protection class:	Class of protection I

For a large drawing of **item 169784** please click on the thumbnail-picture:

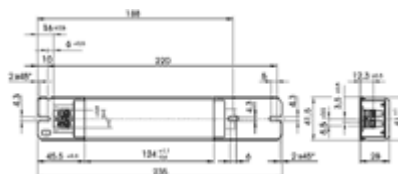

Unit: 10 pcs.

tw 130

EN 60920 (Safety)

EN 60921 (Working method)