


## Technical data



### 81208T2

Complete thrust bearing

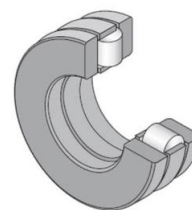

Needle roller bearing, thrust cylindrical roller bearing, 812 series

#### VISUAL (S)

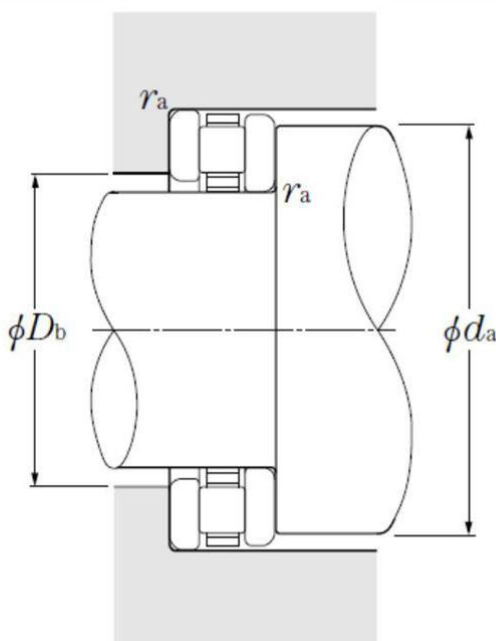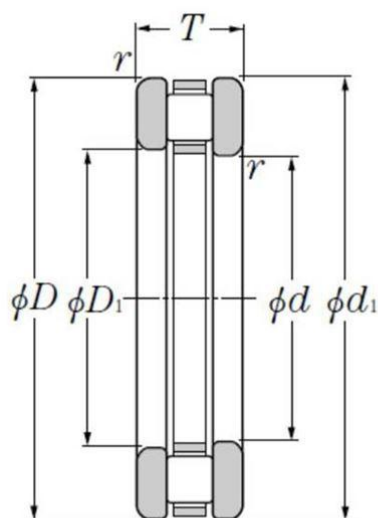

#### PRODUCT DEFINITION

|                                                  |       |
|--------------------------------------------------|-------|
| Brand                                            | NTN   |
| d - Bore diameter of support washer IR - WS      | 40 mm |
| D - Outside diameter of support washer OR - GS   | 68 mm |
| d1 - External diameter of support washer IR - WS | 68 mm |
| D1 - Bore diameter bearing washer OR - GS        | 42 mm |
| T - Thrust bearing height                        | 19 mm |
| Dw - Rolling element diameter                    | 9 mm  |
| Dc1 - Roller cage bore diameter                  | 40 mm |



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                                              |          |
|----------------------------------------------|----------|
| <b>Dc - Roller cage outer diameter</b>       | 68 mm    |
| <b>rs - Min fillet radius</b>                | 1 mm     |
| <b>Cage assembly reference</b>               | K81208T2 |
| <b>Bearing ring (inner ring) WS</b>          | WS81208  |
| <b>Bearing ring (outer ring) GS</b>          | GS81208  |
| <b>Ea - Rollers reference outer diameter</b> | 62,9 mm  |
| <b>Eb - Rollers reference inner diameter</b> | 43,7 mm  |
| <b>Mass</b>                                  | 0,265 kg |
| <b>Cage assembly mass</b>                    | 0,085 kg |
| <b>Bearing ring (inner ring) WS mass</b>     | 0,09 kg  |
| <b>Bearing ring (outer ring) GS mass</b>     | 0,09 kg  |

## PRODUCT PERFORMANCE

|                                               |             |
|-----------------------------------------------|-------------|
| <b>Ca - Dynamic axial load rating</b>         | 74,5 kN     |
| <b>C0a - Static axial load rating</b>         | 190 kN      |
| <b>Cua - Limit axial load rating</b>          | 23,2 kN     |
| <b>N lim - Grease lubrication limit speed</b> | 1100 tr/min |
| <b>N lim - Oil lubrication limit speed</b>    | 4400 tr/min |
| <b>Tmin - Min operating temperature</b>       | -20 °C      |
| <b>Tmax - Max operating temperature</b>       | 120 °C      |

## ABUTMENT

|                                                        |       |
|--------------------------------------------------------|-------|
| <b>da min - Min shoulder diameter IR</b>               | 63 mm |
| <b>Db max - Max OR shoulder diameter</b>               | 44 mm |
| <b>ras max - Max shaft &amp; housing fillet radius</b> | 1 mm  |



# 81208T2

Complete thrust bearing

## ESHOPDONOTDISPLAY

|                                 |                            |
|---------------------------------|----------------------------|
| <b>Tracepart</b>                | Oui/Yes                    |
| <b>Reference</b>                | 81208T2                    |
| <b>Image</b>                    | NRB811_1.jpg, NRB811_3.jpg |
| <b>Rolling element material</b> | Acier 100Cr6               |



### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15