

Features

- Maximum operating pressure is 35 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Steel Nickel-Plated Finish
- Single Shut Off (One side is with valve)
- Euro Profile
- DN7.8
- Flow 1800 l/min
- Compatible with:
TST SWING COUPLING C
TST 026
PARKER - RECTUS 25, 26
CEJN 320
JWL 520, 530
PARKER PEF
LEGRIS

RS PRO Pneumatic Quick Connect Coupling

RS Stock No.: 0325580



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

RS PRO Series 25 Quick Connect Couplings


Pneumatic quick-connect coupling connectors are found across industry in pneumatic systems as diverse as robotic assembly lines and other equipment.

- Maximum operating pressure is 35 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Steel Nickel-Plated Finish
- Single Shut Off (One side is with valve)
- Euro Profile
- DN7.8
- Flow 1800 l/min
- Compatible with:
TST SWING COUPLING C
TST 026
PARKER - RECTUS 25, 26
CEJN 320
JWL 520, 530
PARKER PEF
LEGRIS


Specifications

Manufacturer Series	025
Coupling Type	Quick Connect Coupling Socket
Connection Standard	DN 7.8 Euro Profile
Connection Standard Compatible With	TST SWING COUPLING C; TST 026 ; PARKER - RECTUS 25, 26; CEJN 320; JWL 520, 530; PARKER PEF; LEGRIS
Minimum Operating Temperature	-20°C
Maximum Operating Temperature	+100°C
Maximum Operating Pressure	35bar
Flow	1800 l/min
Flow Direction & Sealing	Self-sealing coupling
Material	Brass, Steel
Finish	Nickel Plated
Connection Type	Hose Barb
Thread Size	N/A
Thread Standard	N/A
Thread Gender	N/A
Coupling Gender	Female, Male
Threaded Connection	N/A
Seal material	Nitrile Rubber
Hose Barb Connection	9mm

Specifications

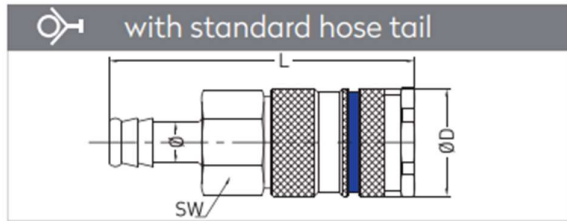

Dimensions (mm)		
SW	L	ØD
19	70.3	23

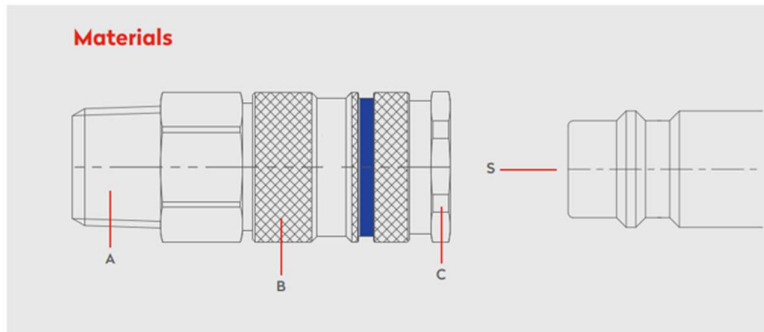



Material Code

A = Brass Nickel Plated

B = Steel Nickel Plated

C = Brass Nickel Plated

S = Steel Nickel Plated

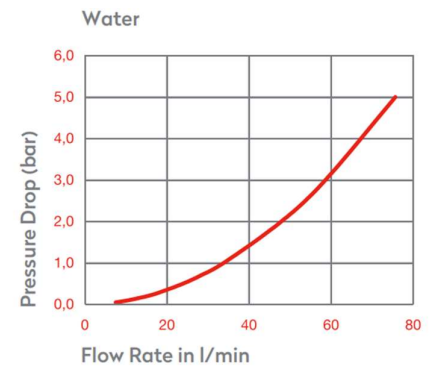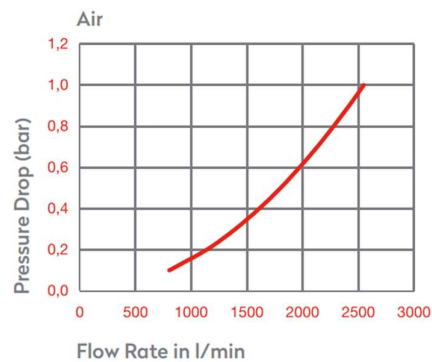

Series 25 Quick Connect Couplings

 


0 - 35 bar
(0-508 PSI)



-20° to +100°C (NBR)
-4° to +212°F

**Shut Off
Type**



OM 250- 00500
OM 100 - 01000
025GCOOM

FLOW

1800 lt/min

DN

7.8 mm