

 
Product selected: Sylproof Superia PC T5 16mmØ 2x54W lamp with A2 ballast

Moisture proof diffuser luminaire. Housing made of polycarbonate. Colour light grey. With top and fitting end cut outs for mains supply and further wiring as well as for through wiring by means of heat resistant internal wiring. Injection mulded diffuser with internal prism for even lighting distribution. Diffuser fixed to the body by using stainless steel clips. Inject gasket for high IP rate. Aluminium reflector. Gear tray made of steel, saved by maintenance cord. D-Mark for electronic ballast version. Polyurethane seal gasket

## Product Image



## Product Line Drawing




Lamp	L	I	H	F
1 x 18/14/24 - 2x14/24	662	92	99	400
1 x 36/28/54 - 2x28	1265	92	99	900
1 x 58/35/49/90 - 2x35/49	1565	92	99	930
1 x 70	1865	92	99	1026
2 x 18	662	137	99	400
2 x 36/54	1265	137	99	900
2 x 58	1565	137	99	930
2 x 70	1865	137	99	1026

## Lamp(s)



## Light distribution

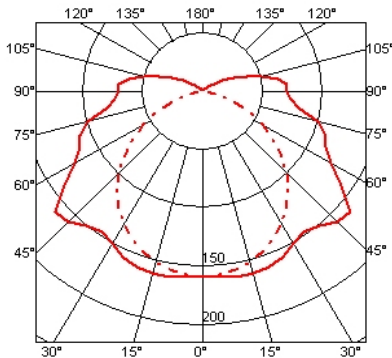

## Product Details

<b>Order code</b>	0056236
<b>Item name</b>	Sylproof Superia PC T5 16mmØ 2x54W lamp with A2 ballast
<b>Mounting</b>	Ceiling pendant, Ceiling surface
<b>Technical description</b>	Polycarbonate body & diffuser. Stainless steel fixing
<b>Place of use</b>	Interior
<b>Colour</b>	Grey
<b>Length (mm)</b>	1265
<b>Width (mm)</b>	92
<b>Height (mm)</b>	99
<b>Weight (kg)</b>	2.6
<b>Housing</b>	Polycarbonate
<b>Shock resistance</b>	2 J
<b>Distribution type</b>	Symmetric
<b>Diffuser finish</b>	Prismatic
<b>Diffuser material</b>	Polycarbonate
<b>LOR (%)</b>	66%
<b>Reflector finish</b>	Aluminium
<b>Reflector material</b>	Polycarbonate
<b>Lamps description</b>	2 x 54W T16 G5
<b>Lamp included</b>	No
<b>Number of heads</b>	1
<b>Control gear availability</b>	Included
<b>Control gear type</b>	Electronic
<b>Control gear description</b>	Electronic ballast with reduced losses
<b>Control gear mounting</b>	Integral
<b>T Class Max</b>	25°C
<b>T Class Min</b>	0°C
<b>Voltage (V)</b>	220-240

## Certifications

