

Datasheet

High Inrush SMD L-Type Chip Fuse Series, 2-6A

RS Pro



Specifications:

Materials

Construction Body Material: Ceramic

Termination Material: Silver(Ag),Nickel(Ni),Tin(Sn)

Fuse Element: Silver(Ag)


Interrupting Ratings

60 amperes at 32V DC

Operating Temperature

-55°C to +125°C

Drawing (mm):

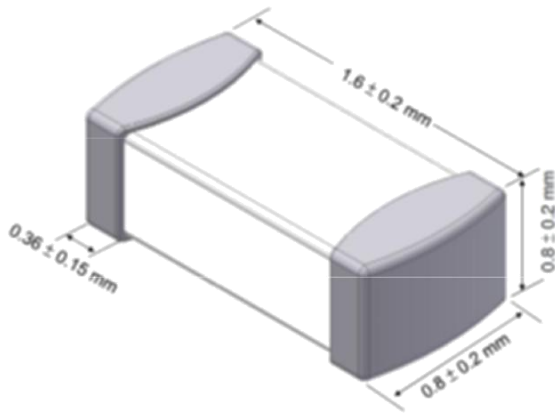

Electrical Characteristic:

Rating	100% Rating		200% Rating		300% Rating		1000% Rating	
	Min.	Max.	Min.	Max.	Min.	Max.	Min.	Max.
2A~6A	4 hrs		1 sec	120 sec		3 sec		0.05 sec

		Nominal Resistance		Nominal Melting I ² t	
		Cold Ohms		A ² Sec	
2	A	0.0364 – 0.0676		0.400	
3	A	0.0182 – 0.0338		1.170	
4	A	0.0105 – 0.0195		2.210	
5	A	0.0070 – 0.0130		2.500	
6	A	0.0049 – 0.0091		5.040	



ENGLISH

Reference:

Stock No	Rating amperes
1747966	2A 32V
1747967	3A 32V
1747968	4A 32V
1747969	5A 32V
1747970	6A 32V