

## HDS 6/15-4 C CLASSIC

HDS 6/15-4 C Classic single-phase hot water high-pressure cleaner in the compact class with a durable crankshaft pump, robust tubular steel frame and offering excellent value for money.



Made in Germany



Order no.

1.030-914.0

- Robust crankshaft pump
- Outstanding price-performance ratio
- Robust tubular steel frame

### Technical data

EAN code		4054278956176
Power supply	Ph / V / Hz	1 / 230 / 50
Flow rate	l/h	300 - 600
Working pressure	bar / MPa	30 - 150 / 3 - 15
Max. pressure	bar	200
Temperature (for supply 12 °C)	°C	max. 80
Connected load	kW	3.6
Consumption of fuel oil at full load	kg/h	3.9
Consumption of heating oil in ecoefficiency mode	kg/h	3.2
Power cable	m	5
Nozzle size		025
Fuel tank	l	30
Weight (with accessories)	kg	108
Weight incl. packaging	kg	118
Dimensions (L × W × H)	mm	1075 × 722 × 915

### Equipment

Spray gun		Standard hot water
High-pressure hose length	m	10
Spray lance	mm	840
Pressure cut-off		■


■ Included in the scope of supply.

This machine requires instruction.




## Robust and long-lasting

- A robust tubular steel frame reliably protects the machine against damage.
- Good accessibility for easy service and maintenance.

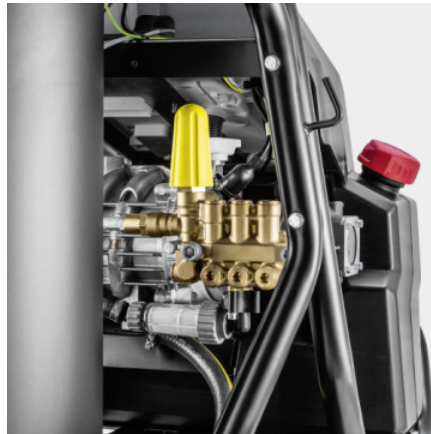

## Reliability

- Robust crankshaft pump with proven Kärcher quality.
- Proven safety technology such as thermo and safety valve and water filter.

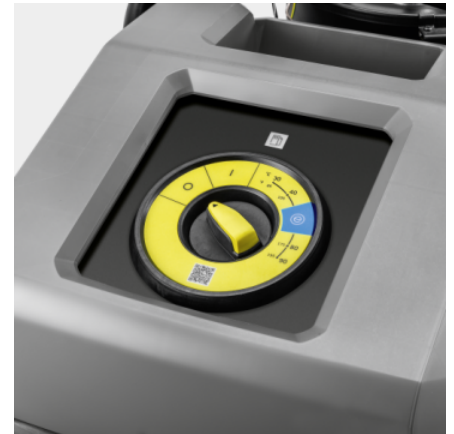


## Efficient burner engineering

- High degree of efficiency with low emissions and long life.
- Long work applications thanks to 30-l fuel tank.
- In ecoefficiency mode, the machine operates in the most economical temperature range (60 °C) - with full water flow.

## ACCESSORIES FOR HDS 6/15-4 C CLASSIC

### 1.030-914.0

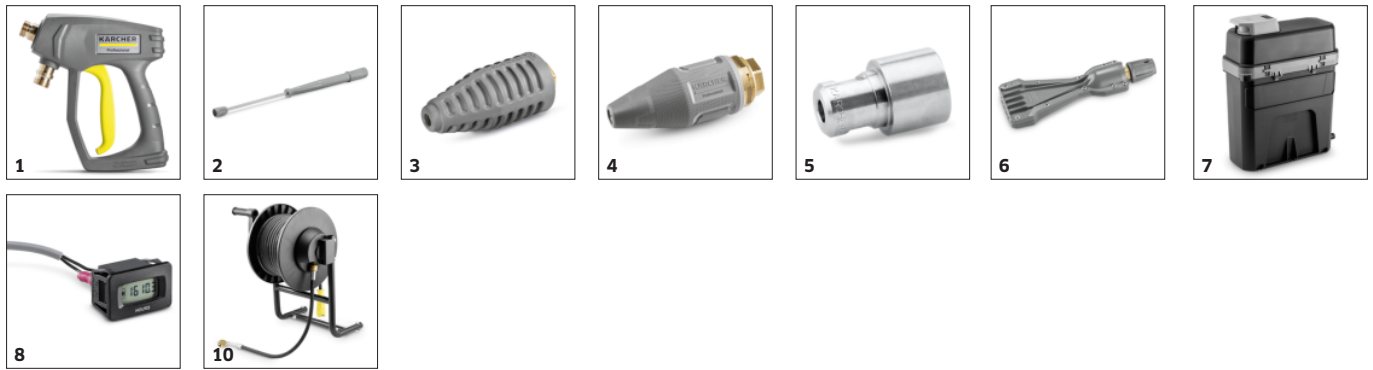

		Order no.	Description	
<b>TRIGGER GUNS</b>				
<b>Spray guns</b>				
Pistol TR 155°C with package	1	4.119-002.0	High-quality Classic spray gun with robust valve. Also suitable for Kärcher hot water high-pressure cleaners.	■
<b>SPRAY LANCES</b>				
<b>Rotating spray lances</b>				
Jet pipe with transport packaging, 840 mm	2	4.119-003.0	Rotating Classic spray lance with ergonomic handle bowls in a robust and high-quality stainless steel design. Also suitable for Kärcher hot water high-pressure cleaners.	■
<b>ROTARY NOZZLES (DIRT BLASTERS)</b>				
<b>Dirt blaster, large</b>				
Dirt blaster, large, 040	3	4.114-041.0	The dirt blaster with rotating pencil jet offers 10 times better cleaning performance. Ceramic nozzle and bearing ring for a long service life. Further data: Max. 300 bar, 30 MPa, 85°C.	■
Dirt blaster Vibrasoft, 050	4	4.114-066.0	Vibrasoft rotary nozzle with rotating point jet for ten times greater cleaning performance. Durable dirt blaster thanks to ceramic nozzle. Reduces vibrations by up to 30% for maximum ergonomics.	□
<b>KÄRCHER POWER NOZZLE</b>				
<b>Power nozzle spray angle 25°</b>				
Power nozzle 25°, 038	5	2.113-006.0	Fan jet nozzle with 25° spray angle, suitable for large areas and removing stubborn dirt and stains.	■
<b>ECOBOOSTER</b>				
eco!Booster TR 040	6	2.113-086.0	eco!Booster with 50% higher area performance than the Kärcher power nozzle; ideal for delicate surfaces. For cold and hot water high-pressure cleaners (nozzle size 040).	□
<b>ADD ON KITS</b>				
Float tank attachment kit for HDS C/M/S-Class Classic	7	2.394-003.0	Float box attachment kit for Classic mobile hot water high-pressure cleaners in the Compact/Medium and Super Class. System care protects against lime deposits and corrosion.	□
Elapsed time counter attachment kit	8	2.853-192.0	Elapsed time counter attachment kit for determining the appliance running time.	□
<b>SEALS FOR TRAPEZOIDAL THREAD</b>				
Gasket set with 9x O-rings for TR thread	9	2.880-001.0		□
<b>HOSE REELS</b>				
<b>Manual hose reel attachment kit</b>				
Add-on kit manual hose reel HDS C/M/S-Class Classic	10	2.639-353.0	Manual hose reel attachment kit for installation on the machine. For safe storage of the high-pressure hoses. Suitable for Classic HDS machines in the compact, medium and super classes.	□

■ Included in the scope of supply. □ Available accessories.