


Geberit Mapress Stainless Steel bend (FKM, blue)



Example image

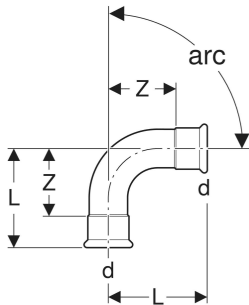

APPLICATION PURPOSES

- For chemicals and technical liquids
- For district heating water $\leq 140\text{ }^{\circ}\text{C}$
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)

- For compressed air (oil purity class 0–4)
- For solar technology, industry and shipbuilding
- For industrial gases (e.g. acetylene, shielding gases)

- Silicone-free (LABS-free)
- Seal ring made of FKM, blue
- Pressing socket with black protection plug

CHARACTERISTICS

- Pressing indicator

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	arc °	L cm	Z cm
50222	12	15	45	2.8	0.8
50223	15	18	45	2.9	0.9
50224	20	22	45	3.2	1.1
50225	25	28	45	3.7	1.4
50226	32	35	45	4.3	1.7

Art. no.	DN	d _g mm	arc °	L cm	z cm
50227	40	42	45	5.1	2.1
50228	50	54	45	6.2	2.7
50231	65	76.1	45	10.1	4.8
50232	80	88.9	45	11.7	5.7
50233	100	108	45	14.3	6.8
50282	12	15	90	3.8	1.8
50283	15	18	90	4.2	2.2
50284	20	22	90	4.7	2.6
50285	25	28	90	5.7	3.4
50286	32	35	90	6.8	4.2
50287	40	42	90	8	5
50288	50	54	90	10	6.5
50291	65	76.1	90	15.7	10.4

Art. no.	DN	d _ø mm	arc °	L cm	Z cm
50292	80	88.9	90	18.4	12.4
50293	100	108	90	22.6	15.1