

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1110251201](#)
Status: **Active**
Overview: [CXP Interconnect System](#)
Description: iPass+ High-Speed Channel (HSC) CXP Cable Assembly, 12X Quad Data Rate (QDR), 84 Circuits, 1.00m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E72548

General

Product Family Cable Assemblies
 Series [111025](#)
 Assembly Configuration Dual Ended Connectors
 Comments Hot Pluggable, Pull to Release Style Latch
 Connector to Connector InfiniBand 12x Both Ends, iPass-to-iPass
 Overview [CXP Interconnect System](#)
 Product Name InfiniBand, iPass+
 UPC 883906021290


Physical

Cable Length 1.0m
 Circuits (Loaded) 84
 Gender Male-Male
 Lock to Mating Part Yes
 Material - Metal Zinc Alloy
 Material - Plating Mating Gold
 Net Weight 292.660/g
 Packaging Type Bag
 Single Ended No
 Wire/Cable Type Twinax

Electrical

Current - Maximum per Contact 0.5A
 Impedance 100Ω
 Voltage - Maximum 30V AC

Material Info

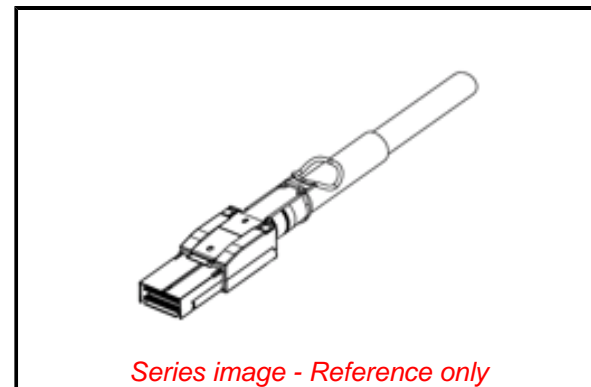

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/01/2018 (15
 January 2018)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[111025](#) Series

Mates With

[76105-0584](#) iPass+ 84 Circuit Connector