

Preinsulated Double Crimp Ring Terminals




General features

- ✓ Tin-plated copper.
- ✓ Barrel with funnel entry.
- ✓ Grooves in the barrel for a better electrical contact and a better tensile strength.



“S” double crimp series:

- ✓ Copper sleeve for crimping insulation giving better resistance to vibration.
- ✓ Polycarbonate insulation sleeve.
- ✓ Max. operating temperature: +125°C.
- ✓ Flammability rating: UL94V0.

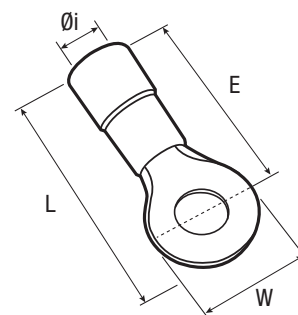

	mm ²	Bulk packing		x100 /Box		Ø mm	Ø mm	W	Ø i	E	L
		Item code	Part No.	Item code	Part No.						
● 0.34 - 1.5	7220020	SA3		7220017	B100SA3	3.6	3	5.6	1.7	14.5	17.3
	7220025	SA3,5		7220026	B100SA3,5	3.6	3.5	5.6	1.7	14.5	17.3
	7220018	SA0-3		7220019	B100SA0-3	3.6	3	7	1.7	17	20.5
	7220030	SA0-4		7220029	B100SA0-4	3.6	4	7	1.7	17	20.5
	7220040	SA0-5		7220043	B100SA0-5	3.6	5	7	1.7	17	20.5
	7220021	SA1-3		7220027	B100SA1-3	3.6	3	8	1.7	17	21
	7220024	SA1-3,5		7220022	B100SA1-3,5	3.6	3.5	8	1.7	17	21
	7220031	SA1-4		7220032	B100SA1-4	3.6	4	8	1.7	17	21
	7220041	SA1-5		7220042	B100SA1-5	3.6	5	8	1.7	17	21
	7220051	SA2-5		7220052	B100SA2-5	3.6	5	12.5	1.7	20.7	27
	7220061	SA2-6		7220062	B100SA2-6	3.6	6	12.5	1.7	20.7	27
	7220071	SA2-8		7220072	B100SA2-8	3.6	8	12.5	1.7	20.7	27
	7220073	SA2-10*		7220074	B100SA2-10*	4	10	13.6	1.7	23.5	30.3
	● 1 - 2.5	7220080	SB3		7220079	B100SB3	4.3	3	5.6	2.4	14.2
7220084		SB3.5		7220085	B100SB3.5	4.3	3.5	5.6	2.4	14.2	17
7220094		SB0-4		7220096	B100SB0-4	4.3	4	8	2.4	17	21
7220100		SB0-5		7220104	B100SB0-5	4.3	5	8	2.4	17	21
7220081		SB1-3		7220082	B100SB1-3	4.3	3	8.6	2.4	16.7	21
7220091		SB1-4		7220092	B100SB1-4	4.3	4	8.6	2.4	16.7	21
7220101		SB1-5		7220102	B100SB1-5	4.3	5	8.6	2.4	16.7	21
7220111		SB1-6		7220112	B100SB1-6	4.3	6	8.6	2.4	16.7	21.3
7220121		SB2-5		7220122	B100SB2-5	4.3	5	12.5	2.4	20.7	27
7220131		SB2-6		7220132	B100SB2-6	4.3	6	12.5	2.4	20.7	27
7220141		SB2-8		7220142	B100SB2-8	4.3	8	12.5	2.4	20.7	27
7220143	SB2-10*		7220144	B100SB2-10*	4.8	10	13.6	2.4	20.7	30.3	
● 2.6 - 6	7220151	SC1-3		7220153	B100SC1-3	6.4	3	9.6	3.3	22.2	27
	7220161	SC1-4		7220160	B100SC1-4	6.4	4	9.6	3.3	22.2	27
	7220171	SC1-5		7220170	B100SC1-5	6.4	5	9.6	3.3	22.2	27
	7220181	SC1-6		7220183	B100SC1-6	6.4	6	9.6	3.3	22.2	27
	7220190	SC2-5		7220188	B100SC2-5	6.4	5	13.8	3.3	25.1	32
	7220191	SC2-6		7220193	B100SC2-6	6.4	6	13.8	3.3	25.1	32
	7220201	SC2-8		7220203	B100SC2-8	6.4	8	13.8	3.3	25.1	32
	7220211	SC2-10		7220213	B100SC2-10	6.4	10	13.8	3.3	25.1	32
	7220214	SC2-12		7220216	B100SC2-12	6.4	12	19.5	3.3	30	40

* polyamide insulation