


Datasheet

RS Pro 300W Fixed Installation DC-AC Power Inverter Pure sine, 24V dc / 230V ac

Stock number: 179-3326

RoHS  

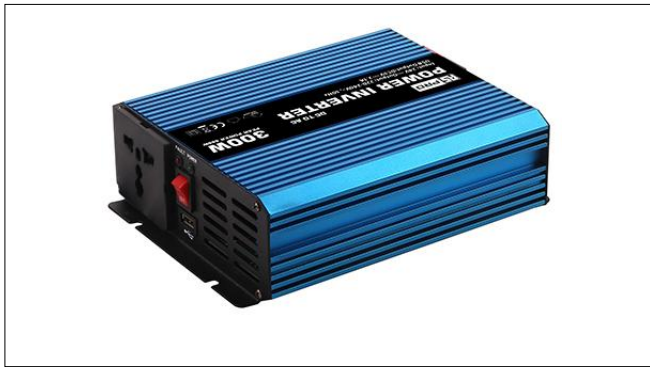

Specifications:

Model	179-3326
Rated power	300W
Surge power	600W
Output voltage	230V
Output frequency	50Hz \pm 3
Output waveform	Pure sine wave
USB port	5V 2.1A
Input voltage	24V
Dimension (LxWxH)	215x150x58mm
N.W/unit	1400g

Features:

- Anodized aluminum case provides durability & max heat dissipation
- Two LED indicators on the front panel shows the working and failure state
- ON/OFF switch control the inverter by hand
- The inverter is compact, light weight and east to operate.
- Protections: overheat, overload, low-voltage alarm & shutdown, over-voltage, short circuit, reverse polarity
- Soft start
- Auto. Reset after being in protected
- Universal UK/Euro output socket.

