

RAMSES 746 S


Item no.: 7460300



Climate control
Room thermostats

Description

- Electronic room thermostats for all types of heating, e.g. gas, water, electric heating etc.
- Snap function, easy installation without screws
- Temperature control via control wheel
- Switch for on/off + indicator light
- Dimmable and switchable LEDs
- Rings under the adjustment wheel to limit the target temperature
- Temperature setting range 5 ... 30°C
- Matching cover frames for various switch ranges (can be ordered separately)
- External temperature reduction possible via control with time switch

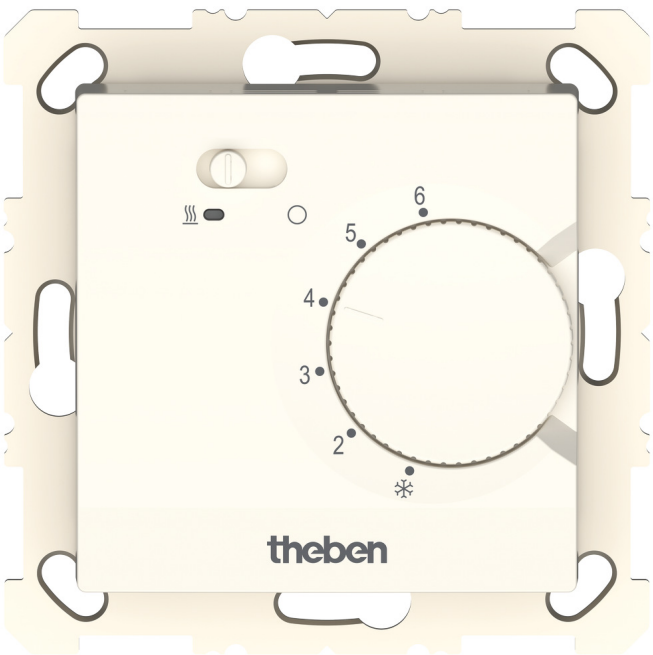


Technical data

RAMSES 746 S	
Operating voltage	230 V AC
Frequency	50 - 60 Hz
Type of contact	NC contact
Switching output	Not potential-free
Switching capacity	10 A (at 230 V AC, $\cos \varphi = 1$)
Setting range temperature	5°C ... 30°C
Function	Electronic

RAMSES 746 S	
Hysteresis	–
Control accuracy	± 0.25 K
Colour	White (similar RAL 9010)
Installation type	Flush-mounted
Type of protection	IP 40
Protection class	II according to EN 60 730-1

Connection example

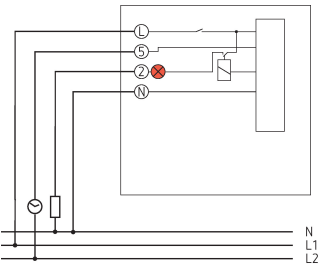

Subject to technical changes and misprints

additional information at: www.theben.de/product/7460300



The load data are determined with exemplary selected illuminants and are therefore typical data due to the large number of available products.

RAMSES 746 S

Item no.: 7460300

theben

Scale drawings

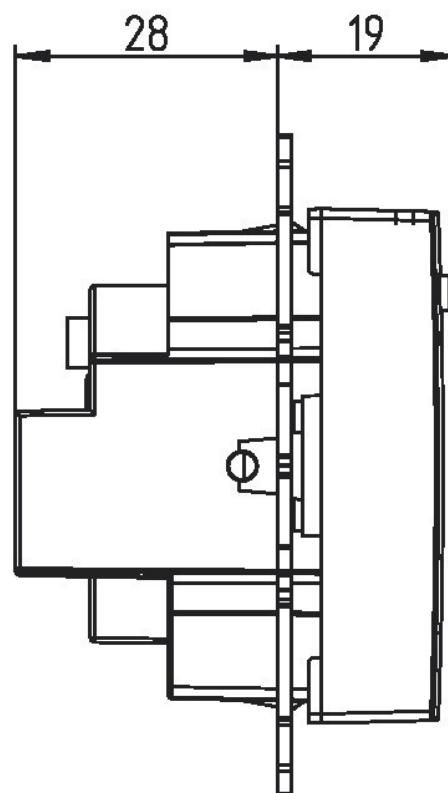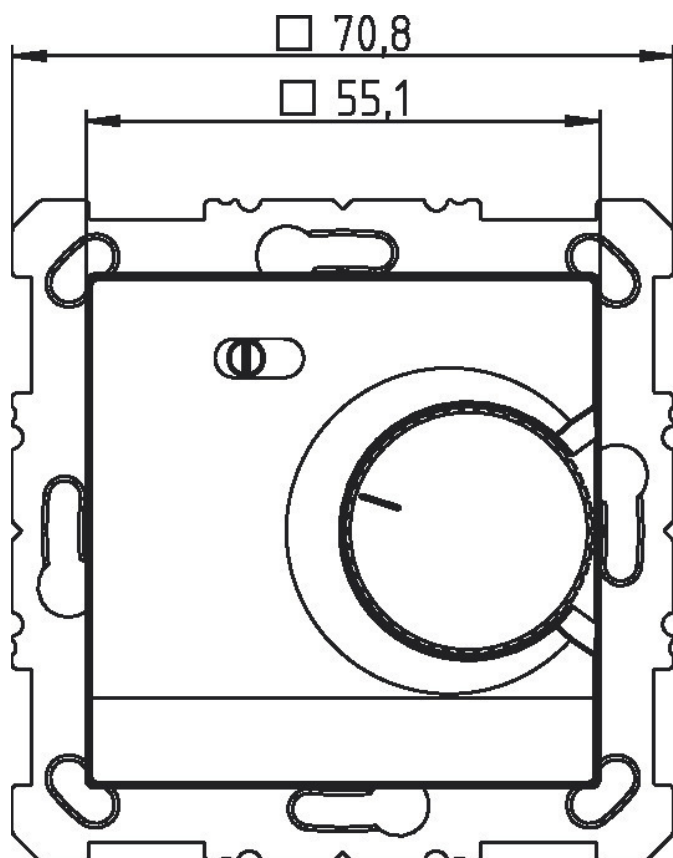

Accessories

Actuator ALPHA 5 230 V

Item no.: 9070441



Subject to technical changes and misprints

additional information at: www.theben.de/product/7460300

The load data are determined with exemplary selected illuminants and are therefore typical data due to the large number of available products.

10/11/2025

Page 2 of 2