



ENGLISH

Data sheet

Stock No. 122-8898

RS PRO 20W RECHARGEABLE LED WORK LIGHT




Specifications:

Working Power	20W
LED Chip/ Brand	SMD/SANAN
Lumen output	1600lm
CCT	5000K
CRI	>80
Beam Angle	120°
Power supply	Li-ion 7.4V 8800mAh
Work time	100%-1.7h/30%-5h/50%-3.5h
Charge Input	100~240V 50/60Hz 0.6A
Charge Output	8.6V 1.2A
Charge Time	4.5h

Features:

- 1、 Dual 112 Ultra Bright SMD LEDs
- 2、 Button with 3 settings: High/Low/Saving mode;

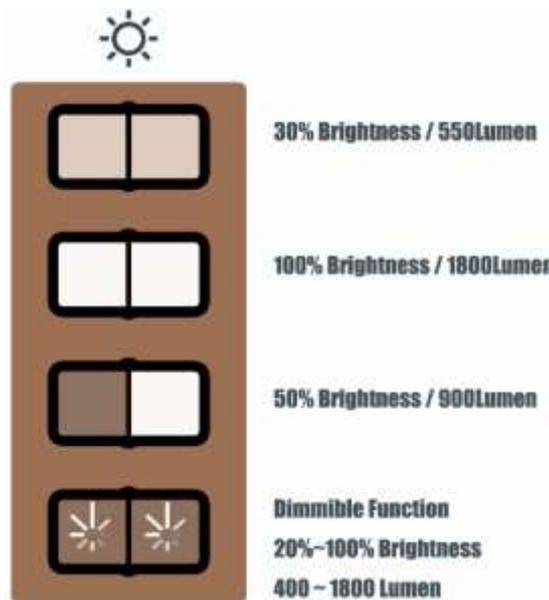

- 3、 IP65 Weather Resistant and could be used for outdoor;



- 4、 IK08 Impact Resistant Hard Case
- 5、 Light angel could be 180 degree



Product size:



Optional accessory: Metal stand (RS article 1228901)

