

## Datasheet

ENGLISH


# RS PRO DC Motor, 95.42 W, 12 V dc, 1035 gcm, 8977 rpm, 6.35mm Shaft Diameter

Stock No: 321-3192



## Specifications:

Supply Voltage	12V
Power Rating	95.42 W
Output Speed	8977 rpm
Shaft Diameter	6.35mm
Maximum Output Torque	1035 gcm
Length	69mm
Dimensions	51.8 (Dia.) x 69mm
Current Rating	10.6 A
Weight	595g

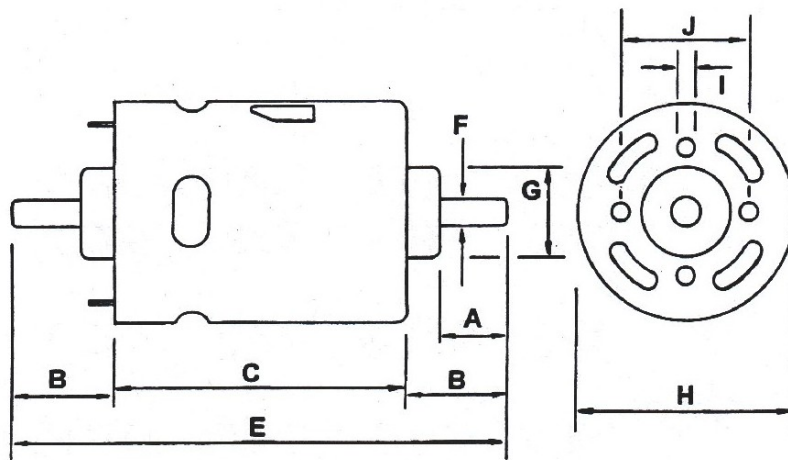

Dimensions	A	B	C	E	F	G	H	I	J
mm	13.2	20.5	69	110	6.35	21.75	51.8	M5	32

Stall Current RE-850 at 12v = 61.34A