


Features

- It is ideal for single or in-line cabinets with single or double doors.
- Made of reinforced polyamide, it resists corrosion and opens 180°.
- It features a captive pin and is screw mounted.

RS PRO Hinges

RS Stock No.: 0726445

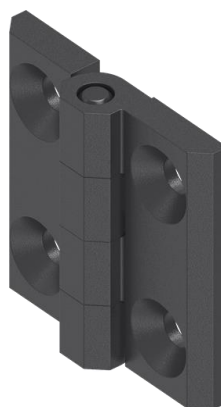

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

The 1056-U42 hinge is used for industrial cabinets and electrical enclosures. It is ideal for single or in-line cabinets with single or double doors. Made of reinforced polyamide, it resists corrosion and opens 180°. It features a captive pin and is screw-mounted.

General Specifications

Material	polyamide GF
Hinges Type	Screw-on
Closing Type	Free movement
Fixing Method	Screws
Pin Style	Fixed
Finish	Black
Handed	Left; Right
Colour	Black
Applications	Single / In-line cabinets with single or double door

Mechanical Specifications

Length	50mm
Width	50mm
Fixing Hole Sizes	6.3x90
Radial Load	305 Nm
Axial Load	585 Nm
Recommended Tightening Torque	5 Nm
Weight	17g
Pin Thickness	5 mm
Knuckle Diameter	12 mm
Pin Diameter	5 mm
Opening Angle	180°
Screw Gauge	M6
Fixing Centres	30 mm