


Datasheet

RS 2 Core Screened Microphone Cable, 30 V, 2 x 4mm od , 0.078 mm² CSA

RS Stock No. 749-2538

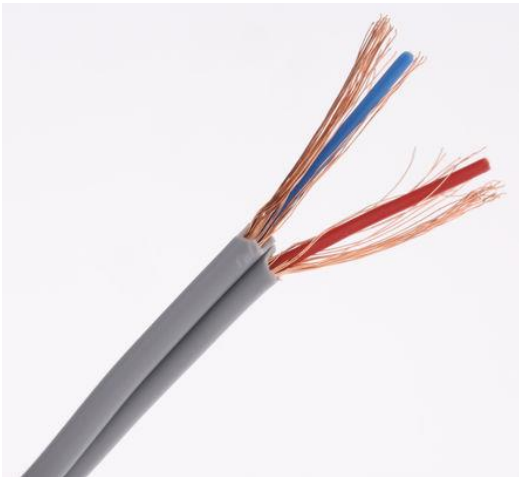

Product Description

Application:

For communication and signal control systems.

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Twin

Cable Construction

Conductor	Bare Copper
Construction	0.1±0.005x10
Stranded Dia.(±0.015mm)	0.36
Insulation	PE
Thickness	0.32
Insulation Dia.(±0.1mm)	1.00
Insulation Color	Red ; Blue

Spiral

Construction (mm)	Bare Copper 0.10±0.003×30
coverage	≥91%

Jacket

Thickness(mm)	PVC ≥0.4
Dia.(±0.15mm)	2.0×4.0
Jacket Color	Grey(RAL7001)


Marking

Twin individual lapped screen cable ww/yy +Meter marking

PACKAGING

100M/Reel 25M/Reel

Design

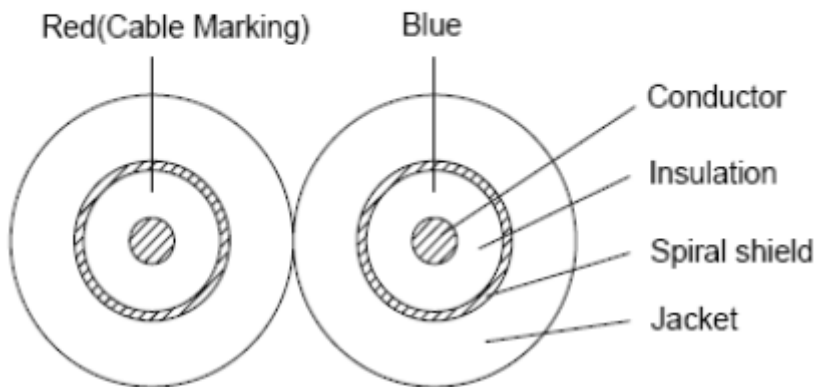

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω/Km)	237
Min.Insulation DC Resistance at 20 °C (MΩ *Km)	>500
Rated Temperature(°C)	-20 to +60
Rated Voltage(V)	30
Capacitance(pF/m)	126±5