


multi-pin plug distributor NEDU-L4R1-M8G3L-M12G8

Part number: 574586

FESTO

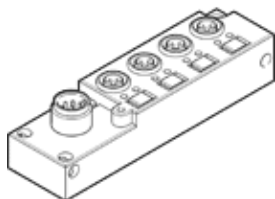

Data sheet

| Feature | Value |
|---|----------------------------|
| Width | 24 mm |
| Height | 23 mm |
| Length | 87 mm |
| Ready status display | Green LED |
| Status display | Yellow LED |
| Assembly position | Any |
| Product weight | 58 g |
| Electrical connection 1 | Straight socket, M8, 3-pin |
| Electrical connection 2 | Straight plug, M12, 8-pin |
| Operating voltage range DC | 10 ... 30 V |
| Acceptable current load at 40°C | 3 A |
| Current-carrying capacity per slot | 2 A |
| Protection class | IP68 |
| Ambient temperature | -20 ... 80 °C |
| Materials note | Conforms to RoHS |
| Corrosion resistance classification CRC | 3 - High corrosion stress |
| Material housing | PBT-reinforced |
| Housing colour | Grey |
| Material seals | FPM |
| Material electrical contact | Nickel and gold plated |
| Material socket | Nickel-plated brass |