




Connectors > PCB Connectors > Wire-to-Board Connectors > Wire-to-Board Connector Assemblies & Housings

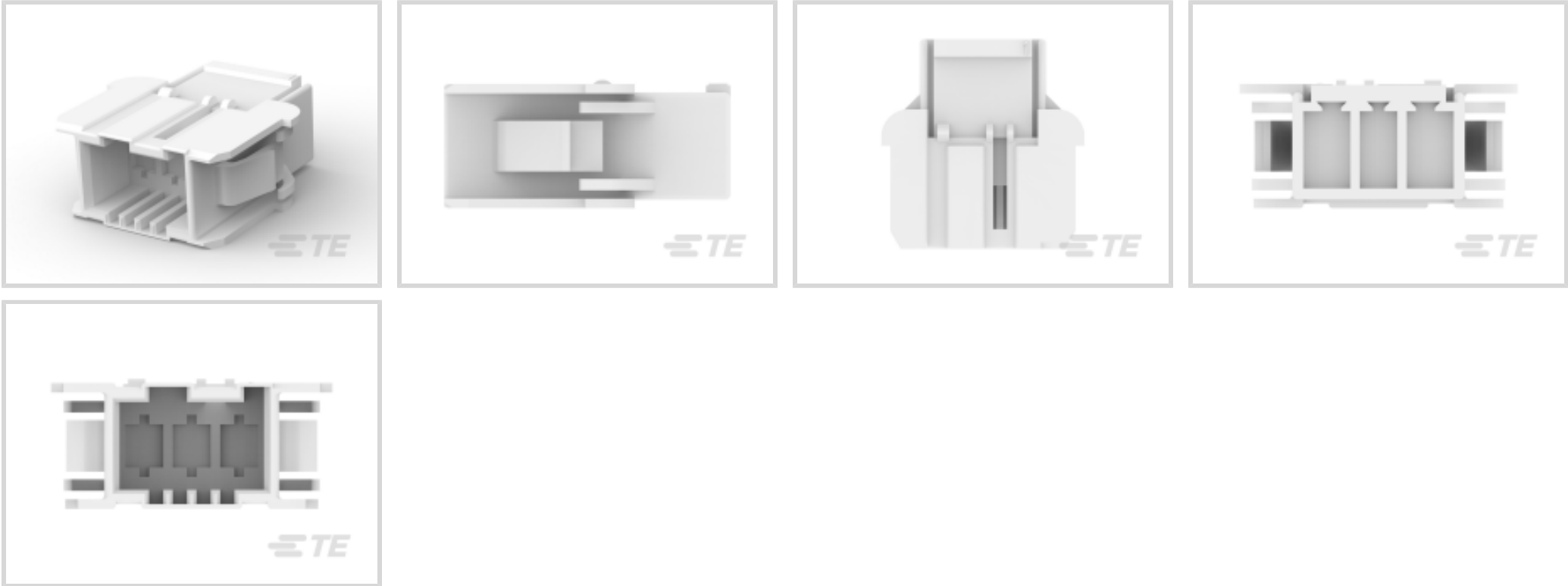

Connector Product Type: **Housing**
Connector & Housing Type: **Plug**
Connector System: **Wire-to-Wire**
Number of Positions: **3**
Centerline (Pitch): **5 mm [.197 in]**

Features

Product Type Features

Connector Product Type	Housing
Connector & Housing Type	Plug
Connector System	Wire-to-Wire
Sealable	No
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	3
Number of Rows	1

Body Features

Primary Product Color	Natural
-----------------------	---------

Mechanical Attachment

Panel Mount Feature	With
Panel Mount Feature Type	Latches
Connector Mounting Type	Panel Mount



Housing Features

Centerline (Pitch)	5 mm[.197 in]
--------------------	---------------

Usage Conditions

Operating Temperature Range	-25 – 105 °C[-13 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Power & Signal
---------------------	----------------

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




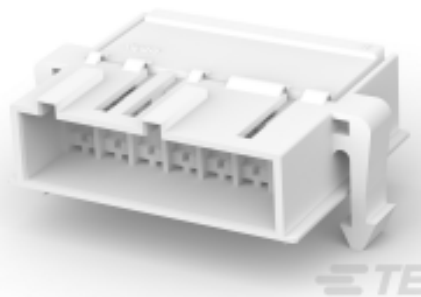


TE Part # 293014-1
7 POS. FASTIN FASTON TAB HSG

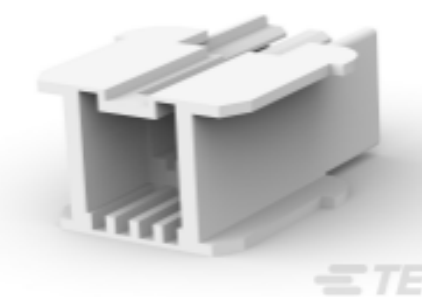


TE Part # 1-928230-2
2 POS FASTIN/ON HOUSING PANEL MOUNT

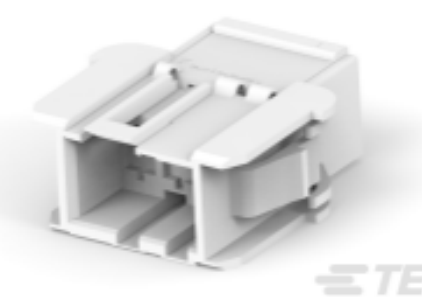

TE Part # 5-927742-3
3P FF FLACHSTGH6,3

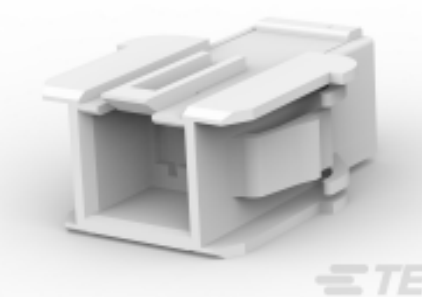


TE Part # 8-927742-2
2POS FASTIN FASTON HOUSING

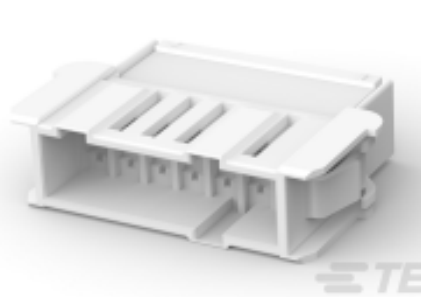


TE Part # 293044-1
7 POS. FASTIN-FASTON* TAB HOUSING, RAST5



TE Part # 293008-5
3 POS. FASTIN-FASTON CONN. TAB HOUSING R

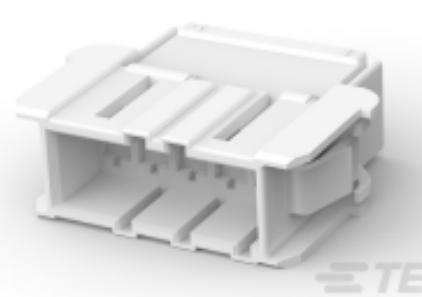

TE Part # 293010-4
5 POS. FASTIN-FASTON CONN. TAB HOUSING R

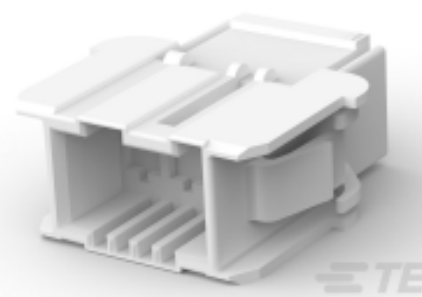


TE Part # 293008-3
3 POS. FASTIN-FASTON CONN. TAB HOUSING R




TE Part # 1-1241968-5
FASTIN FASTON HOUSING 10P




TE Part # 8-927742-6
6 POS FASTIN/ON HOUSING PANEL MOUNT

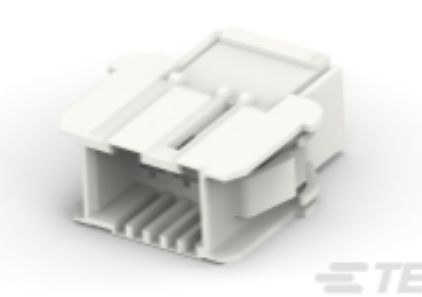


TE Part # 1-293008-1
3 POS. FASTIN-FASTON CONN. TAB HOUSING R

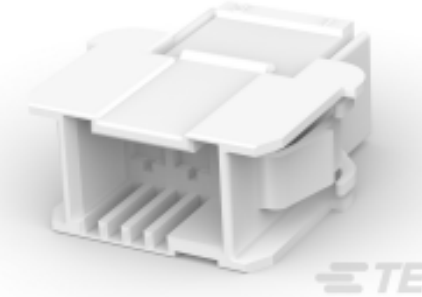


TE Part # 1955416-1
3 POS. FASTIN-FASTON CONNECTOR TAB HOUSI

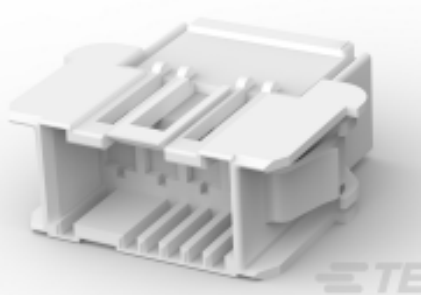

TE Part # 293009-1
4 POS. FASTIN-FASTON CONN. TAB HOUSING R

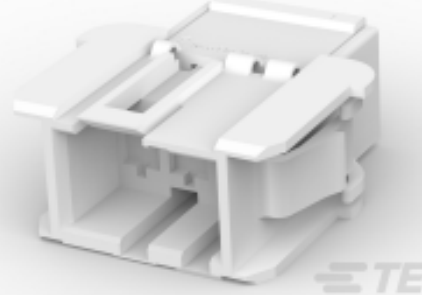


TE Part # 9-927742-3
FASTIN FASTON HOUSING 3POS

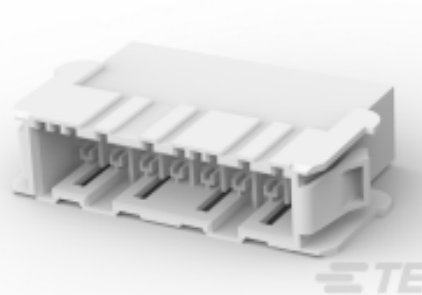


TE Part # 5-1241967-8
FASTIN FASTON TAB HOUSING 8P


Customers Also Bought

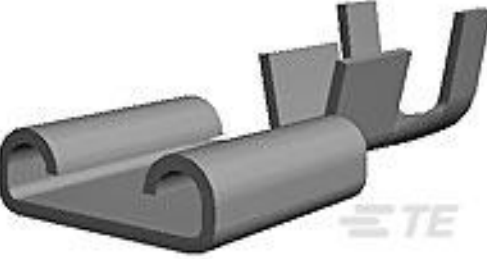

TE Part #6-160432-0
250 FASTON REC 20-16 AWG TPBZ

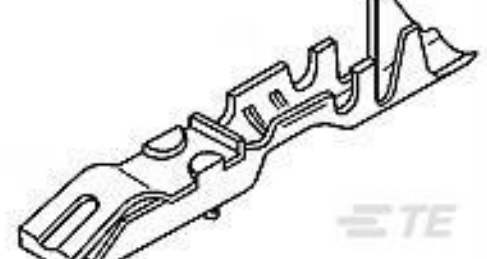

TE Part #867052-2
LOCKING CLIP CONT ASSY .025 SQ

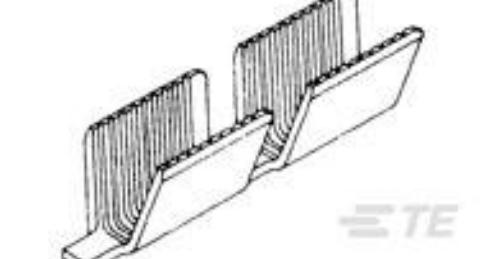


TE Part #62308-2
AMVAR SPLC 3000-7000 020TPBR




TE Part #1-180984-2
FASTON 250 BOOT NYLON BLK



TE Part #794274-1
04P UMNL WIRE SEAL

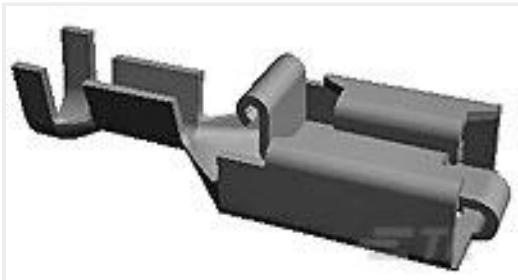


TE Part #154718-6
250 PL MKI REC. 18-14AWG PTPB

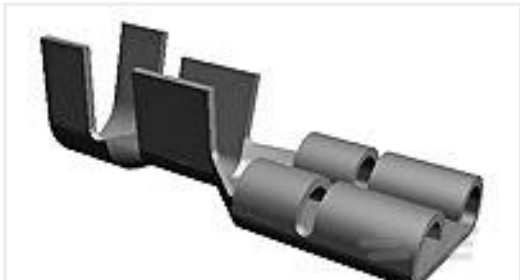


TE Part #444334-1
250 FASTON REC 22-18 AWG BR



TE Part #4-280050-1
250 FASTON, FLAG, REC., 16-20 AWG, BR

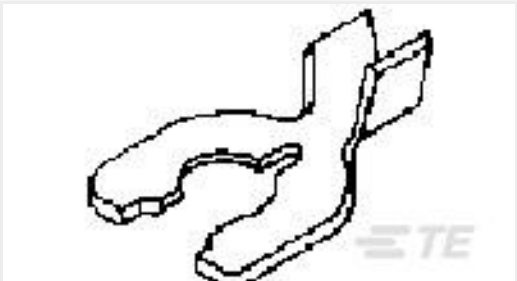

TE Part #485073-1
SPADE TERMINAL 20-16 AWG TPBR

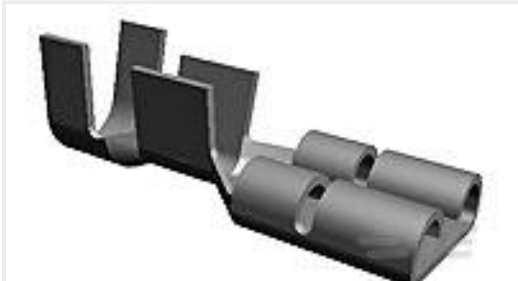

TE Part #444335-1
250 FASTON REC 16-14 AWG BR

Documents

Product Drawings

3 POS. FASTIN-FASTON CONN. TAB HOUSING R

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_293008-1_D.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_293008-1_D.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_293008-1_D.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

FASTIN_FASTON_Product_Line

English

RAST Connector System Catalog

English

Product Specifications

Product Specification

English



[Agency Approvals](#)

[VDE Certificate](#)

English