


# ENCAPSULATED LINEAR CHASSIS- MOUNTING PSU

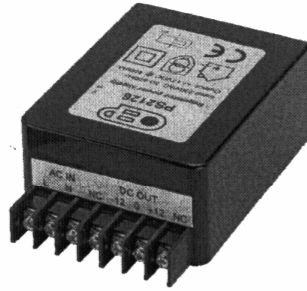

## Features:

- ◆ Chassis mounting with threaded inserts
- ◆ Screw terminal connections
- ◆ Short circuit protection
- ◆ Regulated output
- ◆ Epoxy resin encapsulated
- ◆ 230V Primary winding
- ◆ CE marked
- ◆ Dimensions: 121x69x51mm high

Part Number	Input Voltage	Output Voltage	Output Current	Maximum Power Output	Maximum Ripple / Noise	Line / load Regulation	Over Voltage Protection
PS2125	230V	5Vdc	1A	5 watts	2mV RMS	+/- 0.15%	Yes
PS2126	230V	+/-12Vdc	+/-400mA	9.6 watts	1mV RMS	+/-0.05%	No
PS2127	230V	+/-15Vdc	+/-500mA	15 watts	1mV RMS	+/-0.05%	No

## OXFORD ELECTRICAL PRODUCTS LTD

15-17 Industrial Estate, Wroslyn Road, Freeland, Witney, Oxon, OX29 8SN England  
 Tel: (01993) 886200 Fax: (01993) 886210 e-mail: info@oep.co.uk Web: www.oep.co.uk