


Technical data sheet

Article number:

111-05459

T80L

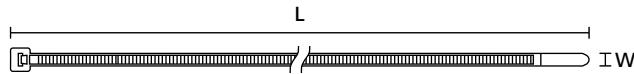

Product Group	Cable Ties for temperatures up to + 105°C (heat stabilised)
Product Family	T-Series in PA66HS natural
Material	Polyamide 6.6, heat stabilised (PA66HS)
Colour	Natural (NA)
Application Tool	ProCut 9 no battery, MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP, EVO9, EVO9SP, EVO9i, EVO9iSP
Bundle Ø max.	110 mm
Bundle Ø min.	1.5 mm
Flammability	UL 94 V2
Halogen-free	Yes
Length (L)	390 mm
Min.Tensile Strength	355 N
Operating Temperature	-40 °C to +105 °C
Package Content	100 pcs.
Package Content packed in	pcs.
Releasable Closure (Yes/No)	No
Specifications	VG 95387 Part 4
Thickness (T)	1.3 mm
Toothing (Serration)	Inside Serrated
UV-Stabilised	No
Variant	Inside Serrated
Weight/Unit	0.0027 kg
Width (W)	4.7 mm

HF ✓ RoHS ✓

VG