
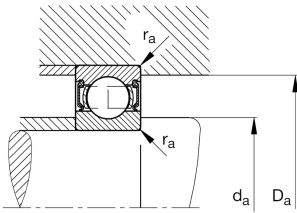


**FAG****61821-2RSR-Y**

Deep groove ball bearing

Deep groove ball bearing 618...-2RSR-Y,
single row, seals, brass sheet metal cage

Technical information

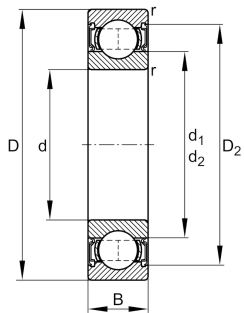

Your current product variant

Sealing	2RSR	Contact seal on both sides
Cage	Y	Brass sheet metal
Tolerance class	PN	Normal (PN)
Dimensional / heat stabilization	S0	Rings dimensional stabilized up to 150°
Lubricant	GA13	Ball bearing and insert bearing grease, standard for D>62mm
Radial internal clearance	CN (Group N)	Normal internal clearance
Bore type	Z	Cylindrical

Main Dimensions & Performance Data

d	105 mm	Bore diameter
D	130 mm	Outside diameter
B	13 mm	Width
C _r	22,100 N	Basic dynamic load rating, radial
C _{0r}	23,600 N	Basic static load rating, radial
C _{ur}	1,320 N	Fatigue load limit, radial
n _G	2,360 1/min	Limiting speed
≈m	350 g	Weight

Mounting dimensions

d _{a min}	109.6 mm	Minimum diameter shaft shoulder
D _{a max}	125.4 mm	Maximum diameter of housing shoulder
r _{a max}	1 mm	Maximum fillet radius



Dimensions

r_{min}	1 mm	Minimum chamfer dimension
D_1	122.11 mm	Shoulder diameter outer ring
D_2	124.2 mm	Caliber diameter outer ring
d_1	113.2 mm	Shoulder diameter inner ring

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	100 °C	Operating temperature max.

Calculation factors

f_0	15.9	Calculation factor
-------	------	--------------------

Characteristics

-  Radial load
-  Axial load in one direction
-  Axial load in two directions
-  Lifetime lubrication, freedom from maintenance
-  Grease Lubrication
-  Sealed on both sides