


ST plugs for cable grommets

of the KT and QT series, diameters 1 - 17 mm

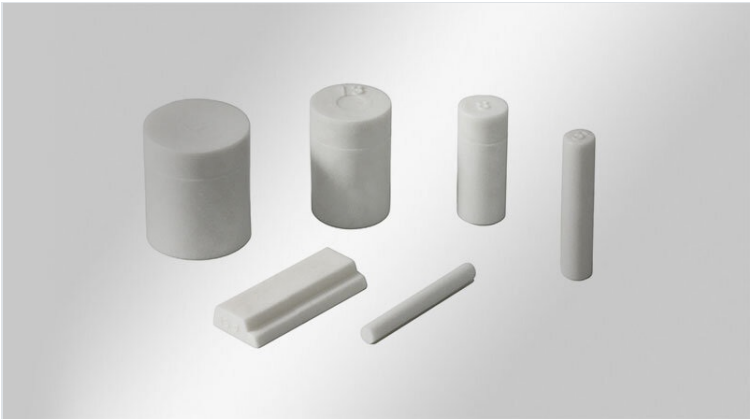

Plugs are used to close either KT or QT grommets which are not equipped with cables. IP ratings of the grommets remain.

Perfect for applications where cables have been removed or might be routed at a later stage.



Specifications

UL Type (UL 50E)	UL Type 12
Material	Polyamide
Flame class	UL94-V0, self-extinguishing
Operating temperature	-40 C° to 120 C°
Properties	silicone free, halogen free


Advantages & benefits

■ Sealing unused cable grommets

Product types & sizes


ST 1		
	Part No.	42900
	EAN	4251269318
		337
	Package quantity	25
	Colour	white
	Length	25 mm
	Diameter D1	1 mm

ST 2

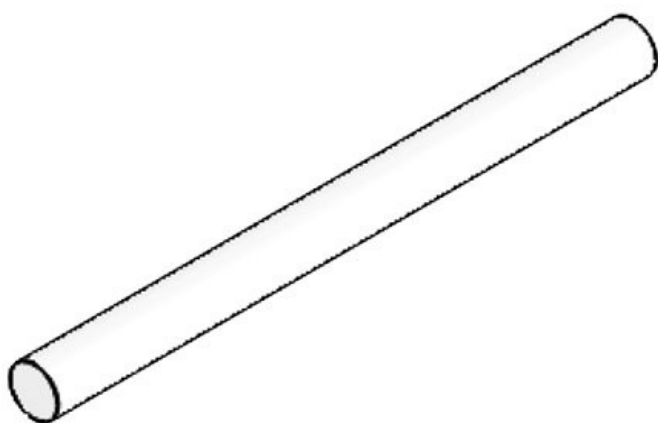


Part No.	42909
EAN	4251269309359
Package quantity	25
Colour	white
Length	25 mm
Diameter D1	2 mm

ST 3

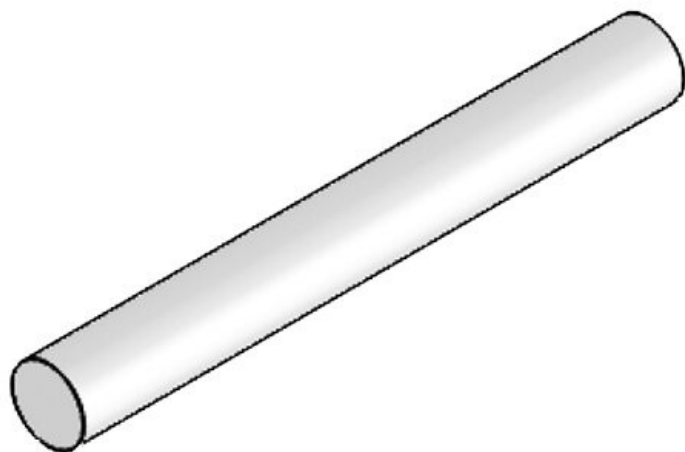


Part No.	42901
EAN	4251269309304
Package quantity	25
Colour	white
Length	25 mm
Diameter D1	3 mm

ST 4

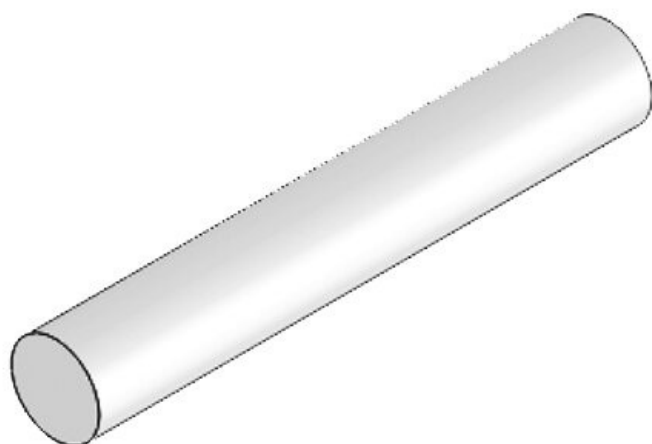


Part No.	42908
EAN	4251269309342
Package quantity	25
Colour	white
Length	25 mm
Diameter D1	4 mm

ST 5

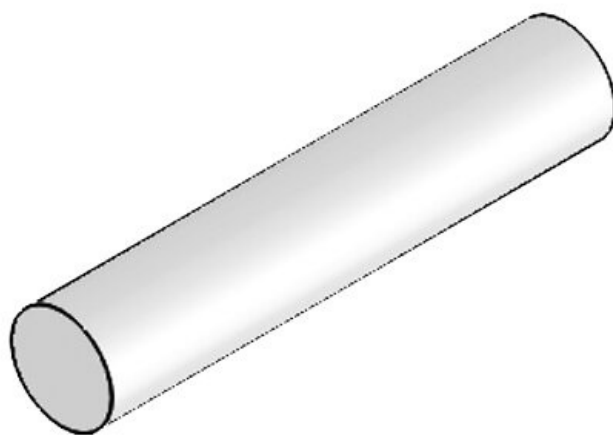


Part No.	42906
EAN	4251269309335
Package quantity	25
Colour	white
Length	25 mm
Diameter D1	5 mm

ST 6

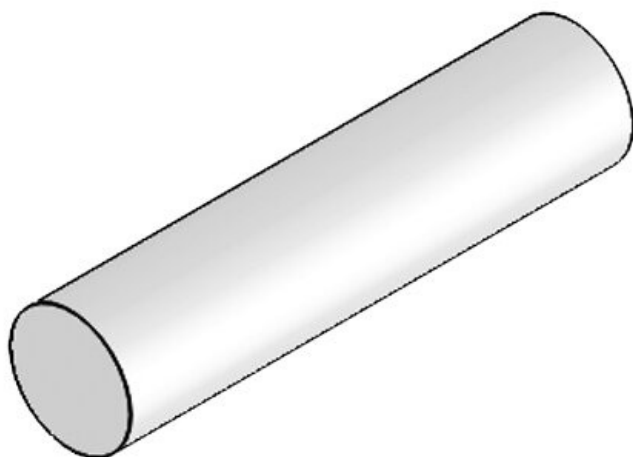


Part No.	42903
EAN	4251269309311
Package quantity	25
Colour	white
Length	25 mm
Diameter D1	6 mm

ST 7

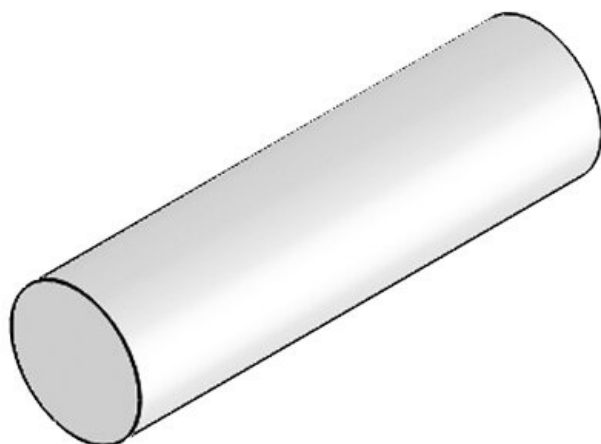


Part No.	42905
EAN	4251269309328
Package quantity	25
Colour	white
Length	25 mm
Diameter D1	7 mm

ST 8

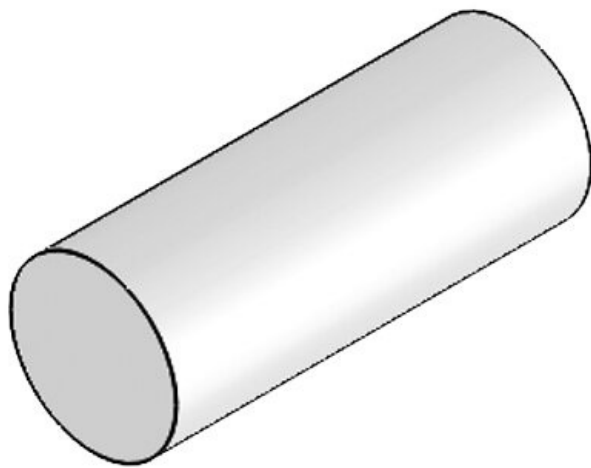


Part No.	42899
EAN	4251269309298
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	8 mm

ST 9

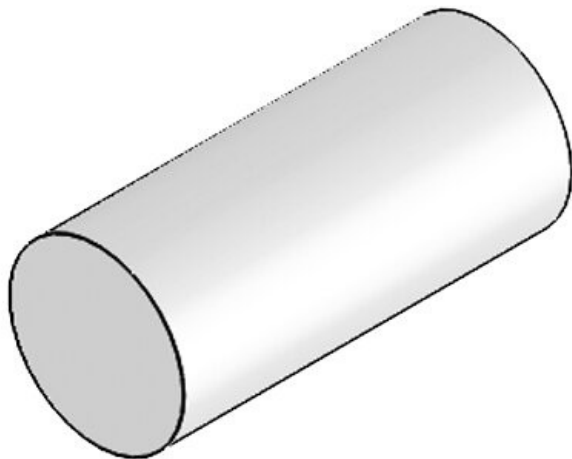


Part No.	42897
EAN	4251269309281
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	9 mm

ST 10

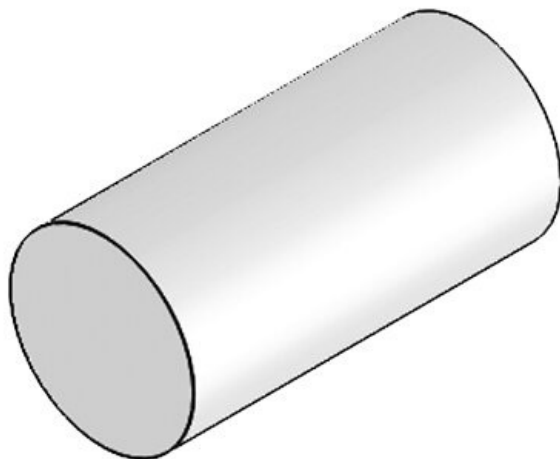


Part No.	42895
EAN	4251269309274
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	10 mm

ST 11

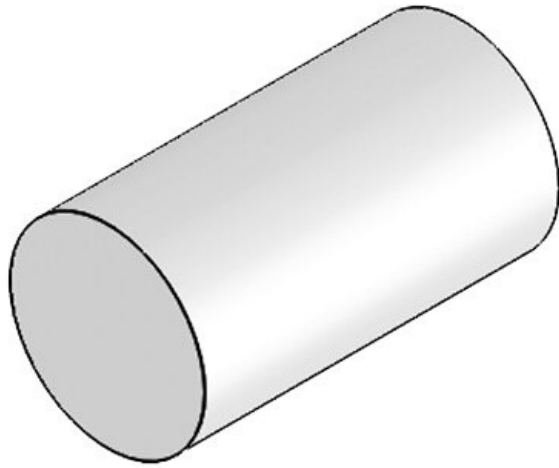


Part No.	42893
EAN	4251269309267
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	11 mm

ST 12

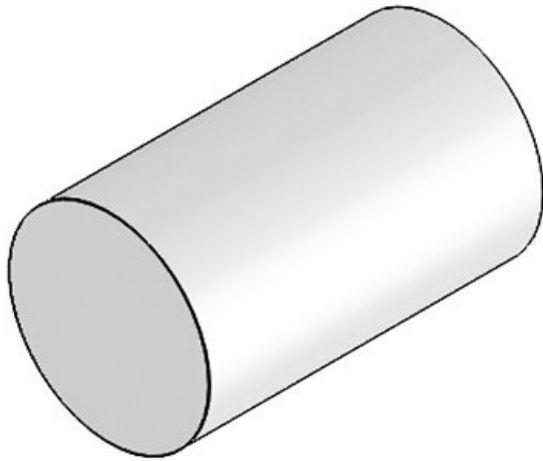


Part No.	42891
EAN	4251269309250
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	12 mm

ST 13

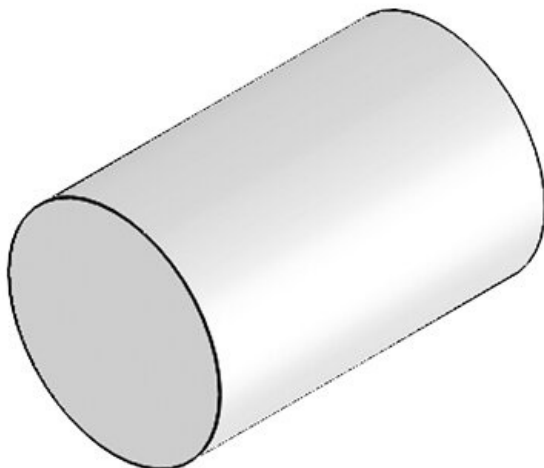


Part No.	42889
EAN	4251269309243
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	13 mm

ST 14

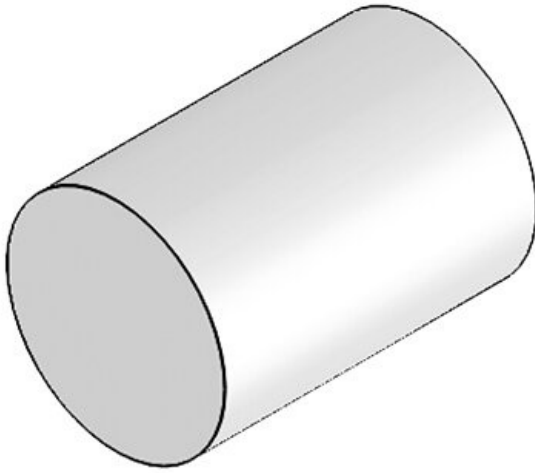


Part No.	42887
EAN	4251269309
	236
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	14 mm

ST 15

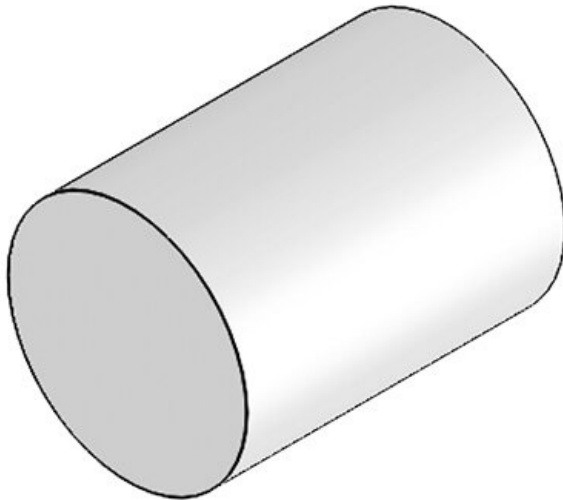


Part No.	42885
EAN	4251269309
	229
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	15 mm

ST 16

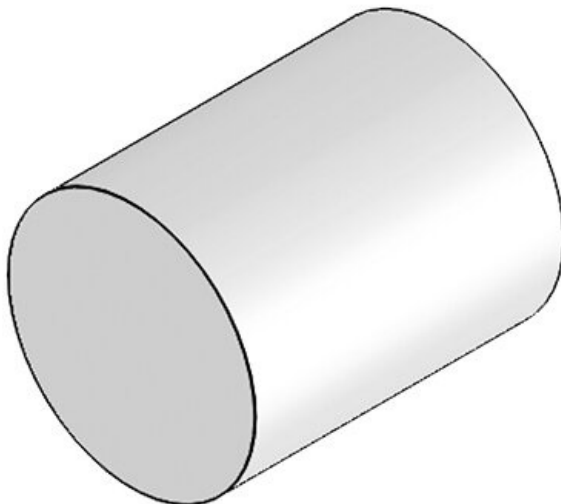

Part No.	42883
EAN	4251269309
	212
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	16 mm

ST 17

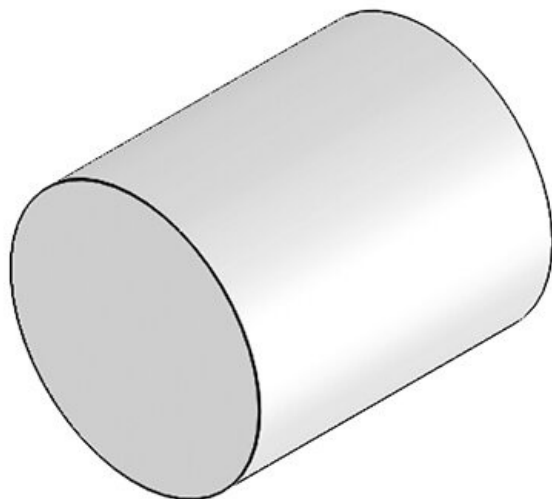

Part No.	42881
EAN	4251269309
	205
Package quantity	25
Colour	white
Length	20 mm
Diameter D1	17 mm

ST-ASI



Part No.	42877
EAN	4251269309
	199
Package quantity	25
Colour	white
Length	25 mm

icotek[®]
smart cable management