

This is a sample photo.

**ORDER SYMBOL:** EKJB 180 T

**EL.number** **EAN:** 6418074013767

Sweden: 2538116

Denmark:

Finland:

**INCLUDING:**

Enclosure body, cover, and 4 slotted cover screws.


**APPROVALS:**

USA: UL Type 1, 12K (E75645 Vol.1 Sec.4); UL 94-V2

EURO: IP 67; UL 94-V2

OTHERS: IEC 529, CE, EEI, SETI 155113-01, GL 83-92, DNV E-4644, LR 90/00196 (E4), BV 2661/3841/B0/0 D

FIBOX EK

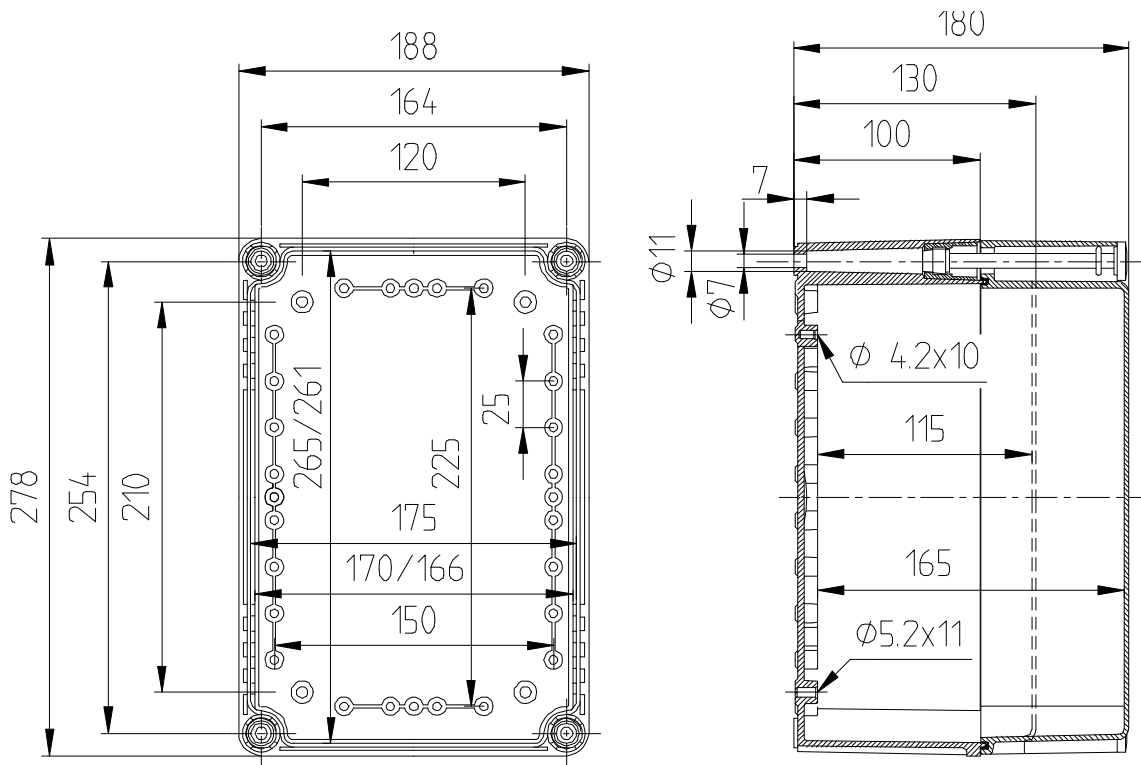

**TECHNICAL INFORMATION:**

Standard colour: RAL 7035

Ingress protection: IP 67 (IEC 529)

Flame resistance:

Temp.range in cont. use: Max. +80 °C

Temp. range of material: - 40 °C - + 120 °C

**ACCESSORIES**

Extension frame	EKJZR	DIN-Rail	EKV 24	Inspection window	L 12	Earth bar support	MB 26069
Extension frame	EKMZR	DIN-Rail	EKV 32	Inspection window	L 12 II	Earth bar set	MR 26059
Extension frame	EKOZR	DIN-Rail	EKV 34	Inspection window	L 13		
Extension frame	EKPZR	Fastening lug	FP 10674	Inspection window	L 24		
Extension frame	EKTZR	Inspection window	L 02	Inspection window	L 24 II		
Extension frame	EKUZR	Inspection window	L 04	Extension frame	MB 10391		
DIN-Rail	EKV 12	Inspection window	L 06	Corner plug	MB 10523		
DIN-Rail	EKV 14	Inspection window	L 08	Ventilation device	MB 10631		
DIN-Rail	EKV 22	Inspection window	L 10	Fastening lug	MB 10674		