




Technical data

RNAB2/8

Roller follower without inner ring

Needle roller bearing, roller follower, with cage, separable, without inner ring, spherical outer ring

VISUAL (S)

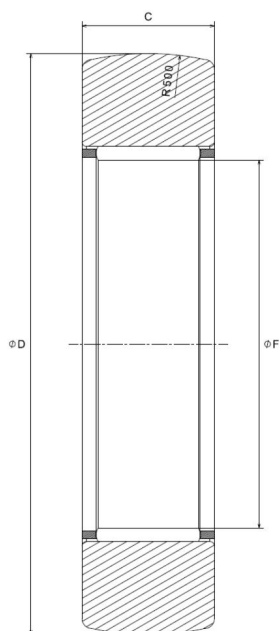

PRODUCT DEFINITION

Brand	NTN
D - External diameter	24 mm
Fw - Under rollers diameter	12 mm
C - Width of bearing, drawn cup or outer ring	9,8 mm
E - Upper roller diameter	15 mm
R - Track roller radius	500 mm
Bearing with/without cage	Avec
Precision class	P0



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

RNAB2/8

Roller follower without inner ring

PRODUCT DEFINITION

Mass	0,021 kg
------	----------

PRODUCT PERFORMANCE

Cr - Dynamic load rating	5,2 kN
C0r - Static load rating	6,4 kN
Track load capacity spherical outer ring	1,89 kN
N lim - Grease lubrication limit speed	12000 tr/min
N lim - Oil lubrication limit speed	16000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	RNAB2/8
Image	NRBRNAB2_1.jpg, NRBRNAB2_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15