



## UCFH204D1

### Modified Flanged Unit, Cast Housing





#### Included products

Bearing	UC204D1	Bearing
Housing	FH204D1	Housing

#### Nominal Dimensions

d	20	mm	Bore diameter
L,L1	62	mm	Overall height
H	42	mm	Height of spherical seat centre
H3	110	mm	Overall height
J	32	mm	Distance between attachment bolts
N	10	mm	Diameter of attachment bolt hole
A2	15	mm	Flange width
A1	13	mm	Flange width
A	25.5	mm	Base width
A0	33.3	mm	Overall width
B,B1,B2	31	mm	Width of inner ring
H1	27	mm	Distance between attachment bolt holes
S	12.7	mm	Distance from Opposite side face of locking device to raceway centre
L1	52	mm	Foot width

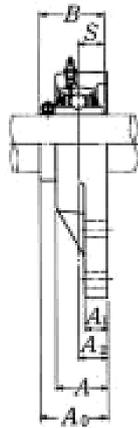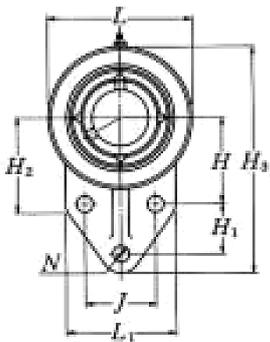

#### Mounting information

G	M8	Bolt size
---	----	-----------

#### Basic Load Ratings

Cr	12.8	kN	Basic dynamic load rating
C0r	6.65	kN	Basic static load rating

#### Mass

mass	0.6	kg	Mass approx.
------	-----	----	--------------