

Cable gland - KV-M-M50-GD-(10)

1636512

<https://www.phoenixcontact.com/in/products/1636512>



Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



HEAVYCON M50 cable screw connection, metal, panel feed-through for data plug, with separable grommet, 1 x 10 mm hole diameter; inside diameter 37 mm

Cable gland - KV-M-M50-GD-(10)

1636512

<https://www.phoenixcontact.com/in/products/1636512>



Technical Data

Product properties

Product type	Full screw connection
Application	for data connectors
No. of conductors	1
Manufacturer	Pflitsch
Manufacturer Designation	25056 dpmk 1/10
Shielded	no

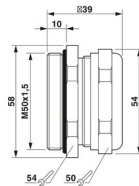
Characteristics

Conductor sealing range	9.50 mm ... 10.00 mm
-------------------------	----------------------

Ambient conditions

Degree of protection	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

Dimensions

Dimensional drawing	
Height	58 mm
Length	39 mm
Length of the connecting thread	10 mm
Wrench size, union nut	50 mm
Wrench size, support	54 mm
Hexagon angular dimension	58 mm
Thread type connection side	M50 x 1.5
Thread pitch	1.5 mm

Internal dimensions

Internal diameter	37 mm
-------------------	-------

Material specifications

Color	silver
Sealing material	TPE
Material, pressure screw	Nickel-plated brass
O-ring material	NBR
Cable gland material	Nickel-plated brass

Cable / line

Cable gland - KV-M-M50-GD-(10)

1636512

<https://www.phoenixcontact.com/in/products/1636512>



External cable diameter	9.5 mm ... 10 mm
Halogen-free	no

Phoenix Contact 2022 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in