


Blue Elastic Rubber Trolley Wheel 250mm, ball bearings, 450kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **571-511-250B25**

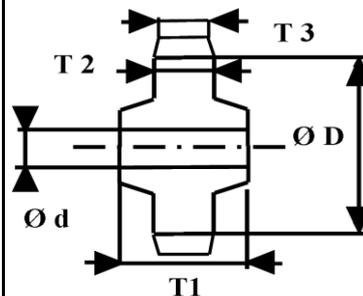

Product Details

Wheel Rim : very thick black polyamide.
Tyre : solid, blue bonded elastic rubber tyre, non marking.
Hub : symmetrical, two ball bearings.

Specifications

Wheel Diameter - $\varnothing D \pm 1\%$	250 mm
Hub Type	two ball bearings
Hub Length T1	60 mm ± 1
Width of Tread T2	50 mm ± 1
Width of Tread-on floor T3	50 mm ± 1
Axle Hole $\varnothing d$	$\varnothing 25$ mm
Hardness of tread A ± 4	A 70 Shore
Load capacity	450 Kg
Temperature	-20 / +60 °C
Weight	1,8 Kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
Resilient with a low starting effort.
Does not leave scratches or other marks on surfaces.
Reduce schok and vibration.
Quiet in use and high wear resistance.
Towable by mechanized vehicle.
Suitable for industrial floors and also all interior floors.