

- Cutters & Pliers
- Wire strippers
- Crimpers
- Tweezers
- Screwdrivers & Wrenches
- Metal working
- Parts boxes
- Tool cases
- Tool kits
- Soldering irons & Solder
- Parts & Solder removal equipment
- Measuring instruments
- Optical equipment
- Antistatic products
- Clean products
- Chemical products
- Maintenance & Safety products
- Precision series
- Miniature cutters
- Plastic cutters
- Standard cutters
- Scissors
- Wire cutters
- Miniature pliers
- Standard pliers
- Lineman's pliers
- Slip joint pliers

## P-15 LONG NOSE PLIERS WITH SIDE CUTTER

P-15-125

P-15-150


- Cutting capacity: Copper wire 2.6mm φ  
Copper stranded wire 2 mm<sup>2</sup>

■ Hardness HRC(blade): 58


■ Weight: P-15-125 100 g

P-15-150 125 g


■ With serrations

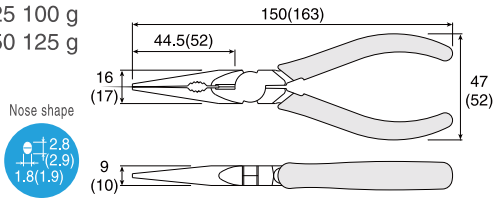

With serrated gripping hole (P-15-150 only)

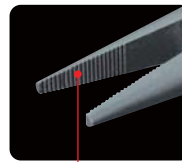

With serrations

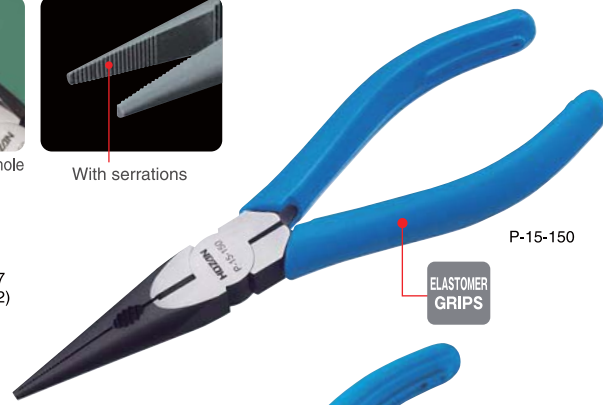

ELASTOMER GRIPS



CUTTER

ELASTOMER GRIPS

P-15-150

## P-14 LONG NOSE PLIERS WITH SIDE CUTTER

P-14-125

P-14-150



- Cutting capacity: Copper wire 2.6mm φ  
Copper stranded wire 2 mm<sup>2</sup>

■ Hardness HRC(blade): 58


■ Weight: P-14-125 100 g

P-14-150 125 g

■ With serrations

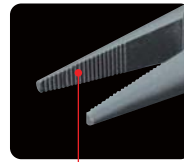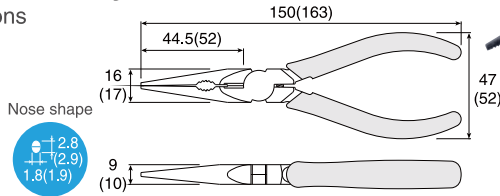

With serrations

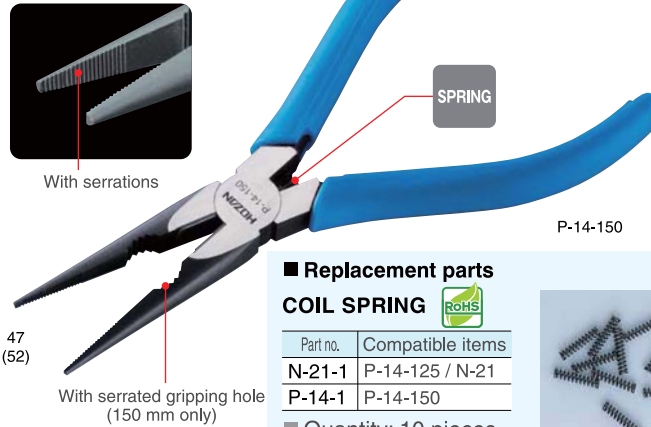

ELASTOMER GRIPS

SPRING



CUTTER

SPRING

P-14-150

### ■ Replacement parts

#### COIL SPRING

Part no.	Compatible items
N-21-1	P-14-125 / N-21
P-14-1	P-14-150

■ Quantity: 10 pieces





## P-22 LONG NOSE PLIERS WITH SIDE CUTTER

- Cutting capacity: Copper wire 2.6mm φ  
Copper stranded wire 2 mm<sup>2</sup>

■ Hardness HRC(blade): 58

■ Weight: 125 g

■ With serrations

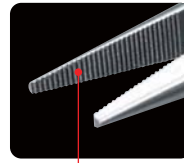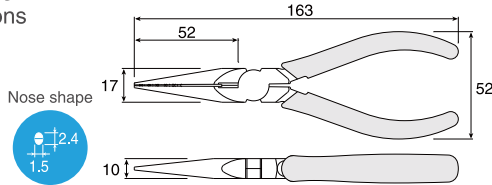

With serrations



ELASTOMER GRIPS




CUTTER

## P-16 FLAT NOSE PLIERS

■ Hardness HRC(tip): 45

■ Weight: 115 g

■ Without serrations

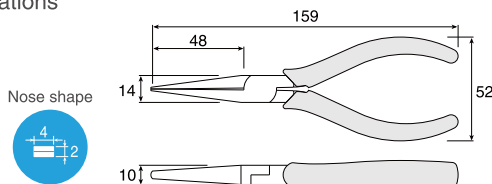


ELASTOMER GRIPS

## P-12 BENT NOSE PLIERS

■ Hardness HRC(tip): 45

■ Weight: 115 g

■ Without serrations

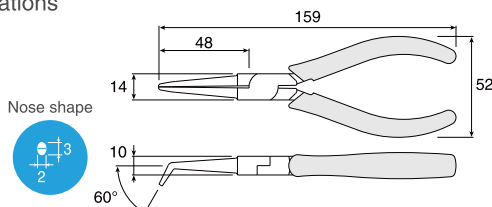

ELASTOMER GRIPS

⚠ Warning ● The handle cover is not insulated. Do not use where electrical currents exist.