


E75227



Push-in T-fitting for pneumatic connections

AirBox push-in T-connect 10pcs

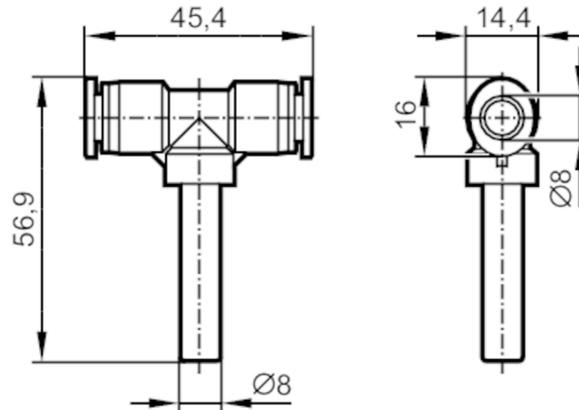

Application

Media compressed air according to ISO 8573-1: 2001

Operating conditions

Operating pressure [bar] 10; (min. -0,95)

Ambient temperature [°C] -20...80

Mechanical data

Weight [g] 120.1

Materials housing: nickel-plated brass / PA66; release ring: polyoxymethylene;
Tooth lock washer: stainless steel; form ring: NBR

Tube fittings 8 mm

Sleeve diameter [mm] 8

Remarks

Pack quantity 10 pcs.