

Universal socket strip 3-fold without power cord with switch

Item-No.: 0201x00032300



Robust plastic, grey

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm


Expanded contact protection by using a shutter

End caps with mounting possibility

Without power cord


Simple screwed connection

Spacious connection chamber, cable entry (Ø 10 mm)

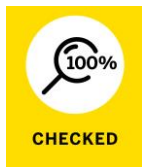

Universal socket strip 3-fold without power cord with switch

Technical data

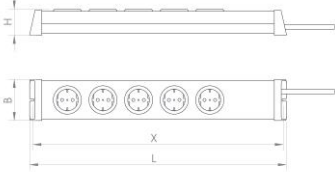3.600 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	16 A Rated current
Power Cord: without power cord Connecting terminals: up to 2,5 mm ² per pole Sockets: earthing contact Type F Switch: 2-pole, illuminated (red) Consumption per switch: < 0,5 W Safety class: IP20		 
 (similar illustration)		
Item-No. 0201x00032300 EAN 4012096024712 PU 10		334 x 74 x 47 mm Dimensions (L x W x H) 326 mm Fixing Dimension