

Linear Double Ended High Wattage

DE 118MM ECO 120V 500W R7S SV1

0021619

Range features



PRODUCT OVERVIEW

Light colour	829 Warm white
Ordering number	0021619
Technology	Halogen
Average life (Rated) (h)	2000
Energy class	C
Lamp shape	Linear
Lamp finish	Clear
Dimmable	Yes
Cap/Base	R7s
Type	Linear Double Ended
EAN code	5410288216195
CRI (Ra)	100
Colour temperature (K)	3000
Luminous flux (Rated) (lm)	8750
Watt (Nominal) (W)	500
Voltage (V)	120

Linear Double Ended High Wattage

DE 118MM ECO 120V 500W R7S SV1

0021619

DATA TABLE

General data

Ordering number	0021619
Technology	Halogen
Average life (Rated) (h)	2000
Average life (Nominal) (h)	2000
Energy class	C
Energy saving lamp	No
Lamp shape	Linear
Lamp finish	Clear
Dimmable	Yes
Cap/Base	R7s
Type	Linear Double Ended
EAN code	5410288216195
E-number FI	4749347
E-number SE	8355600
Product name	DE 118MM ECO 120V 500W R7S SV1
Lamp mercury content (mg)	0
Starting time (max) (s)	0.01
Warm-up time to 60% of full light (max) (s)	Instant full light
Control gear required	No
Fixture rating	Enclosed
IEC Reference	IEC 60357
IEC Reference 2	IEC 60432-3
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	> 8000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

Optical data

Light colour	829 Warm white
CRI (Ra)	100
Suitable for accent lighting	No
Colour temperature (K)	3000
Luminous flux (Rated) (lm)	8750
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	8750

Linear Double Ended High Wattage

DE 118MM ECO 120V 500W R7S SV1

0021619

Electrical data

kWh per 1000 hours burning time	500
Watt (Rated) (W)	500
Watt (Nominal) (W)	500
Voltage (V)	120
Lamp power factor	1

Physical data


Weight (kg)	0.01
Lamp Length (mm) - C/L	119.6
Max. Lamp Diameter (mm) - D	12
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	16.50 x 2.50 x 2.90
Inner package dimensions (L x W x H) (cm)	17.00 x 13.00 x 6.50
Inner package net weight (kg)	0.08
Outer package dimensions (L x W x H) (cm)	37.50 x 28.50 x 19.50

Linear Double Ended High Wattage

DE 118MM ECO 120V 500W R7S SV1

0021619

TECHNICAL DRAWINGS

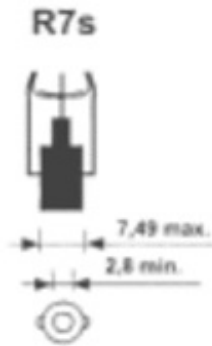

ENERGY LABEL

