




Pipe

Double spigot

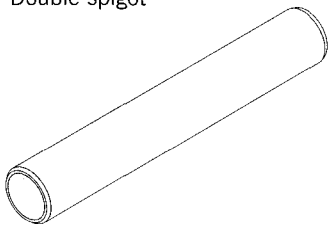

Straight coupling

 Solvent sockets

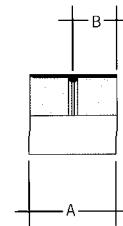



Size mm	Code	Length m
32	♦♦ KP104 ♡	4
40	♦♦ KP204 ♡	4
50	• KP304 ♡	4

Size mm	Code	A	B
32	♦♦ KSC1 ♡	46	20
40	♦♦ KSC2 ♡	53	24
50	• KSC3 ♡	66	28

Expansion coupling /copper adaptor




Ring seal/solvent socket

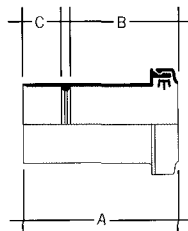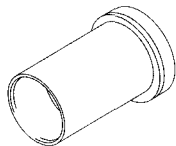

Size mm	Code	A	B	C
32	KEC1	86	61	20
40	KEC2	90	64	23
50	KEC3	82	50	30

Multi-fit to plastic pipework to BS 5255 and BS 5254 and to copper pipework to BS 2871 (metric) and BS 659 (imperial)

 

Pipe clip

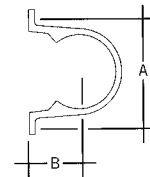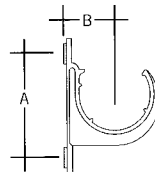

Size mm	Code	A	B
PVC-u (Open)			
32	♦♦ KF1 ♡	57	30
40	♦♦ KF2 ♡	62	30
50	• KF3 ♡	77	41
ABS (Saddle)			
32	• WC3 ♡	57	30
40	• WC4 ♡	64	30
50	WC5	80	41

Bend



Solvent sockets

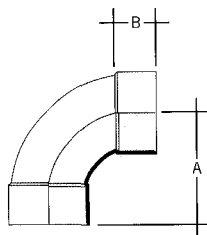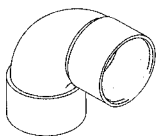

Size mm	Code	Angle	A	B
32	♦♦ KB1 ♡	88½°	57	18
40	♦♦ KB2 ♡	88½°	62	21
50	• KB3 ♡	88½°	78	28

Bend

Solvent sockets

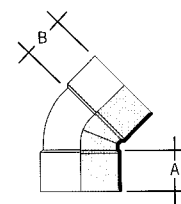
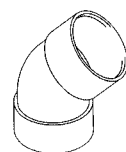


Size mm	Code	Angle	A	B
32	♦♦ KB12 ♡	45°	29	18
40	♦♦ KB22 ♡	45°	33	21
50	• KB32 ♡	45°	42	28

Colours: Available in White only unless indicated. • Available in Black ♦ Available in Chestnut Brown.

Spigot bend


 
Spigot/solvent socket

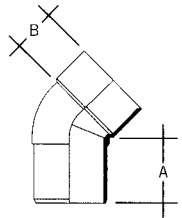

Size mm	Code	Angle	A	B
32	KBA12	45°	24	23
40	KBA22	45°	35	26

Knuckle bend



Solvent sockets

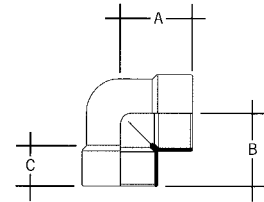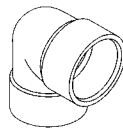

Size mm	Code	Angle	A	B	C
40	♦♦ KBK25 ♡	90°	48	48	23
50	KBK35		see page 11		

Tee



Solvent sockets

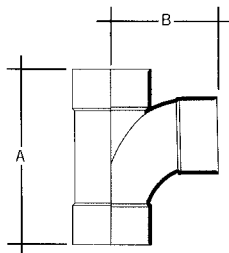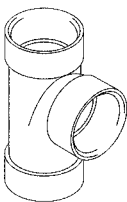

Size mm	Code	Angle	A	B
32	♦♦ KT1 ♡	88½°	92	57
40	♦♦ KT2 ♡	88½°	106	62
50	♦ KT3 ♡	88½°	135	78

Tee



Solvent sockets

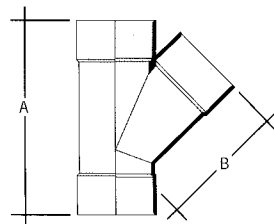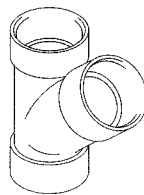

Size mm	Code	Angle	A	B
32	KT11 ♡	45°	102	66
40	KT21 ♡	45°	117	78
50	KT31 ♡	45°	149	100



Cross tee

Solvent sockets

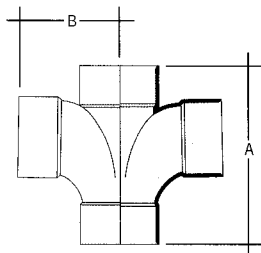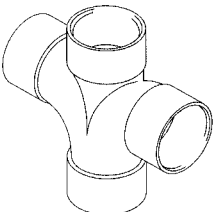

Size mm	Code	Angle	A	B
40	KXT21 ♡	88½°	106	62
50	KXT31	88½°	140	87


 
Access cap

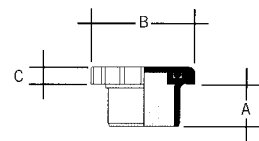

Size mm	Code	A	B	C
32	♦♦ KAP1 ♡	29	53	8
40	♦♦ KAP2 ♡	33	57	8
50	♦ KAP3 ♡	39	71	8

Long spigot bend

 Solvent socket/spigot

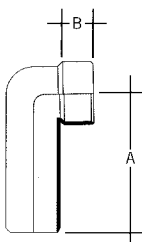



Size mm	Code	Angle	A	B
32	KBS1	87½°	92	18
40	KBS2	87½°	92	23

Colours: Available in White only unless indicated. ♦ Available in Black ♦ Available in Chestnut Brown.

Socket reducer

 
 
Solvent spigot/socket



Size mm	Code	A	B
32x21.5	KR175	22	20
40x32	♦♦ KR210	28	22
50x32	• KR310	32	28
50x40	• KR320	32	28



Durgo automatic air admittance valve

Push-fits into ring seal BS 5255 socket; grey only includes a polystyrene insulating hood

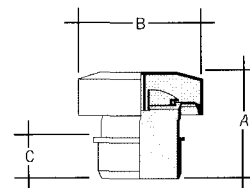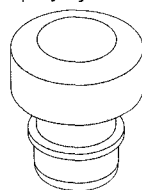

Size mm	Code	A	B	C
50	SVD2	98	82	28

 
 
Vent terminal



Size mm	Code	A	B
50	♦♦ RV225	55	18

Vent slate cap


 
Black rubber

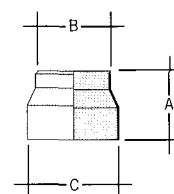

Size mm	Code	A	B	C
50	SV21	51	51	68

Female iron adaptor


 
Solvent socket/BSP thread

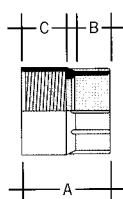

Size mm	Code	A	B	C
32	KFA1	50	25	20
40	KFA2	53	25	24
50	KFA3	60	25	28

Male iron adaptor

 
 
Solvent solvent/BSP thread



Size mm	Code	A	B	C
32	KMA1	44	20	20
40	KMA2	47	20	24
50	KMA3	53	20	28

Caulking bush



Solvent socket

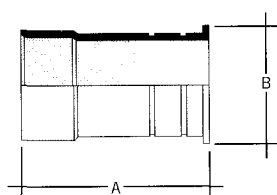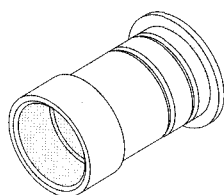

Size mm	Code	A	B
50	KD3	117	70

Cap & lining

Spigot/1¼" BSP nut

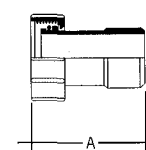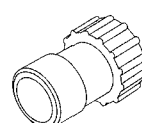

Size mm	Code	A
32	KFC125	58

Colours: Available in White only unless indicated. • Available in Black ♦ Available in Chestnut Brown.