



2690Z0

Headlamp

HeadsUp Lite™



Regardless of the job, the 2690Z0 HeadsUp Lite™ won't leave you in the dark. With 74 lumens of LED light, 11 hours of battery run time and weighing in at 116 gr (4.1 ounces), it's brighter, more efficient, compact and lighter than other headlamps in its class. The no-nonsense rotary bezel switch is easy to operate, even when wearing bulky gloves.

The 2690Z0 is made of impact and chemical resistant Anti-static Impact Modified PC/PBT and it's water resistant for all-weather use. It comes with an adjustable and comfortable cloth strap, as well as a heavy duty rubber strap that will not slip off your helmet.

Being certified to ATEX safe for use in high-risk hazardous locations, Zone 0 (Category 1) areas, the 2690Z0 HeadsUp Lite™ is ideal for professionals who work in chemical, pharmaceutical, power, oil and gas, and fire rescue industries. Get the 2690Z0 HeadsUp Lite™ from Peli.

CONFIGURATIONS

2690Z0 - Standard

DIMENSIONS

Length: 2.81"

MATERIALS

Body: Anti-static Impact Modified PC/PBT


O-Ring: EPDM

Lens: Polycarbonate (PC)

Shroud: Anti-static Impact Modified PC/PBT

Contact Spring Retainer: Nickel-Plated Phosphore Bronze

COLOURS

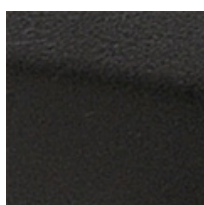






Black

LIGHT SPECS

Lamp Type: LED

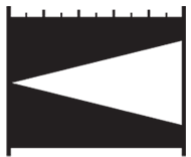Lamp Life: 10000 hrs

FL1 STANDARD	HIGH
	74 LUMENS
	11h 0mins
	92m
	2124cd
	IPX7

POWER

Battery Size: AAA

Battery Type: Alkaline

Battery Quantity: 3

Batteries Included: yes

Volts: 4.5v

WEIGHT

Weight With Batteries: 4.1 oz

Weight Without Batteries: 2.8 oz

SWITCH

Switch Type: One-handed Rotary Switch

Light Modes: On / Off

CERTIFICATIONS

ATEX Zone 0

OTHER

Minimum Pack: 1

Package Code: C

Peli Products, S.L.U.

c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999

info@peli.com • www.peli.com