




Datasheet

RS Pro Variable Capacitor

ENGLISH

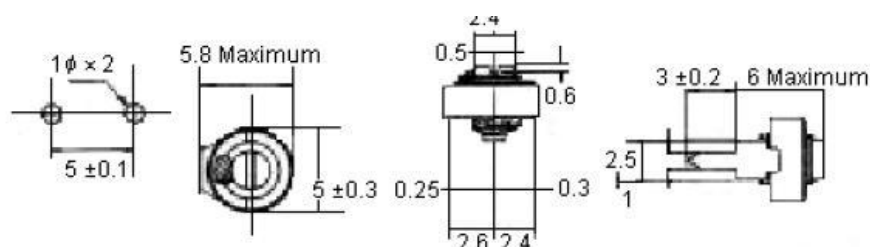

Dimensions : Millimetres

Specifications:

Maximum working voltage	: 200 V dc
Dielectric strength	: 500 V dc at maximum capacitance
Insulation resistance	: 10,000 MΩ at 250 V dc at maximum capacitance
Maximum working temperature	: 85°C

RS Stock Number	Part Number	Colour	Maximum Capacitance (pF)	Minimum Capacitance (pF)	Q (at maximum C) F = 10 MHz	Temperature Co-efficient
247-0372	CV05 A0601	Red	6.0	1.5	300 minutes	NPO ±250
247-0388	CV05 C1201	Nil	12.5	2.8		N600 ±250
247-0394	CV05 D2001	Blue	20.0	3.5		N750 ±300
247-0401	CV05 E3001	Yellow	30.0	5.0		N1500 ±300
247-0423	CV05 E5001	Green	50.0	5.5		N1500 ±500