


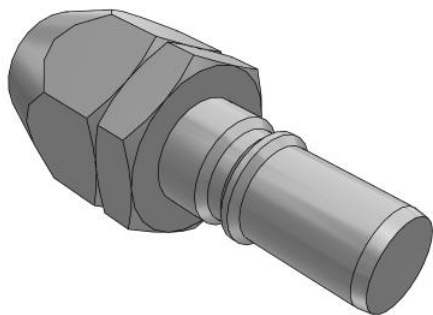

KK*P-*N, S-Couplers, Nut Fitting KK3P-50N

Datasheet


General series information

- Nut Fitting.
- Body size: 1/8, 1/4, 1/2.
- Applicable hose O.D.: ø8, ø9, ø10, ø12, ø12.5, ø16.

Standard specifications

Body Size	3 (1/8)
Applicable Hose I.D./O.D.	5/8 mm
Pressure medium	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	-100 kPa
Proof pressure	1.5 MPa
Maximum ambient temperature	60 °C / 40 °C for Water
Minimum ambient temperature	-5 °C (with no freezing) / 5 °C for Water
Effective Area	3.8 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.021 Kg

Dimensions

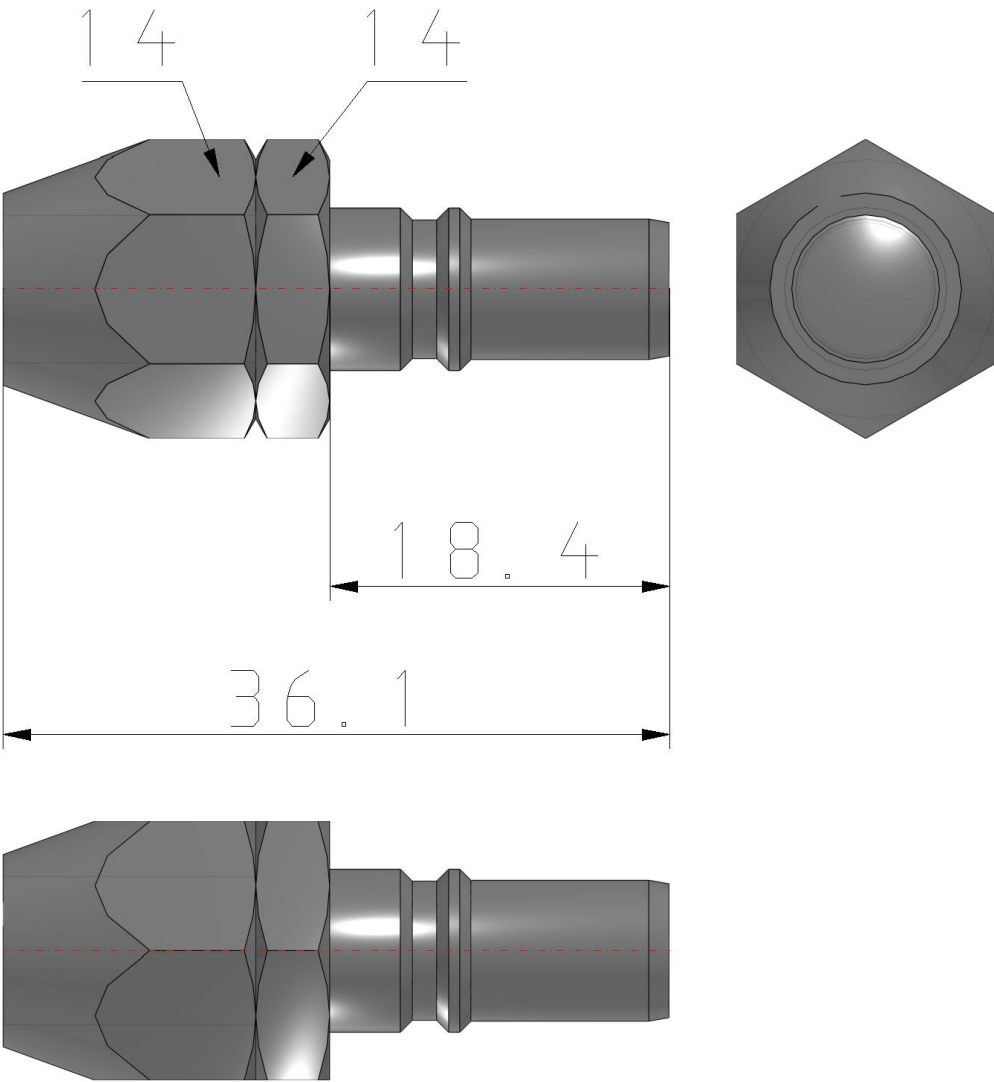

Additional information

Catalogue

[KK-C_EU.pdf](#)