


Datasheet

LED Indicator Lamp

RS Stock number 204-467

Dimensions (mm):

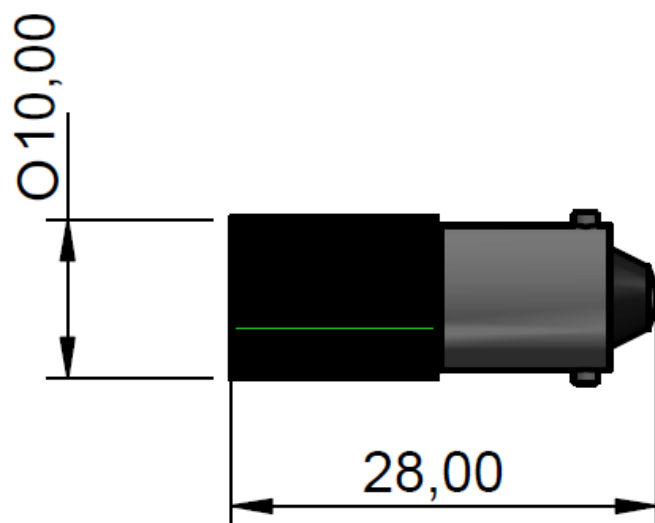

Specifications:

LED/Multiled	Multiled	Optimum voltage (V)	28Vac/dc	Intensity	90mcd
Mounting Size	10x28	Rectifier	Half Wave		
Mounting Finish		AC current	9mA		
Protection	-	DC current	15mA		
Mount Holder	Ba9	Voltage Tolerance (%)	10%		
Chip Qty	8	Optimum temperature (°C)	-30°C...+60°C		
Indicator colour	Green	Storage temperature (°C)	-30°C...+60°C		
Wavelength (nm)	565	Contact Tab	Ba9s		