 



air reservoir VZS-20-B

Part number: 192161

FESTO

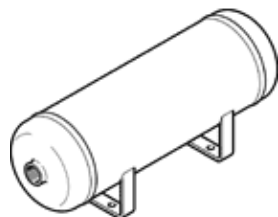

Data sheet

Feature	Value
Volume	20 l
Assembly position	Downward condensate drain
Conforms to standard	EN 286-1
Operating pressure	-0.95 ... 16 bar
CE mark (see declaration of conformity)	to EU directive pressure reservoirs
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-] Nitrogen
Corrosion resistance classification CRC	4 - Very high corrosion stress
Medium temperature	-10 ... 100 °C
Ambient temperature	-10 ... 100 °C
Max. tightening torque, connecting thread	130 Nm
Max. tightening torque, condensate drain	27 Nm
Product weight	9,000 g
Mounting type	with through hole
Condensate drain connection	G3/8
Pneumatic connection	G1
Materials note	Free of copper and PTFE
Material of air reservoir	steel, powder-coated