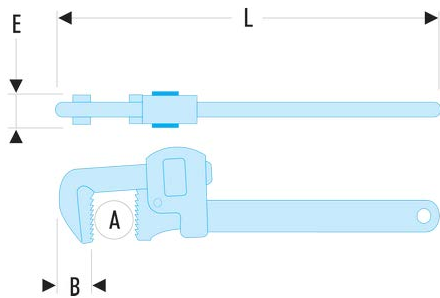


131A.10SLS 131A.SLS - Steel Stillson models**Description :**

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- Capacity: 0 to 102 mm; 0 to 3"1/2.
- Very robust wrench, head hardened to 55 HRc.
- Accurate approach thanks to fine machining of the threads and button, good grip.
- Clé "Stillson" avec trou dans le manche : accrochage directe par mousqueton.
- Mors mobile indémontable pour éviter une perte ou chute.

A maxi [in]:	1
A maxi [mm]:	34
B [mm]:	25,0
E [mm]:	16,0
L ["]:	10
L [mm]:	250
[kg]:	0,625