




## Technical data

WS81207

Thrust washer

Needle roller bearing, thrust needle roller bearing, inner ring

### VISUAL (S)

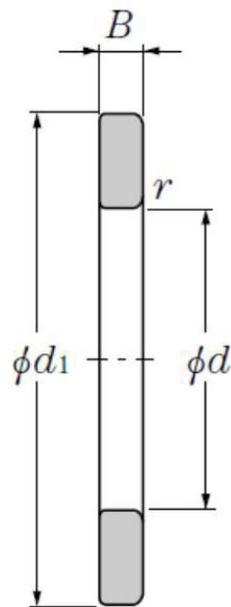

### PRODUCT DEFINITION

<b>Brand</b>	NTN
<b>d - Bore diameter of support washer IR - WS</b>	35 mm
<b>d1 - External diameter of support washer IR - WS</b>	62 mm
<b>B - Ring thickness</b>	5,25 mm
<b>rs - Min fillet radius</b>	1 mm
<b>Bearing ring (inner ring) WS mass</b>	0,085 kg

### PRODUCT PERFORMANCE

<b>Tmin - Min operating temperature</b>	253,15 °K
---	-----------



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

**PRODUCT PERFORMANCE**

**Tmax - Max operating temperature**

393,15 °K

