


Features

- FeCu-Ni "J" Type Thermocouples
- Max. operating temperature 400°C
- Screw Clamp and Spring
- Sensor type DIN/EN60751
- Cable type Fiber glass+Fiber glass+Braided
- Immersion Length 19 x 26 mm
- Cable Length 3meter

RS PRO Screw Clamp and spring "J" Type Thermocouples

RS Stock No: 0350430

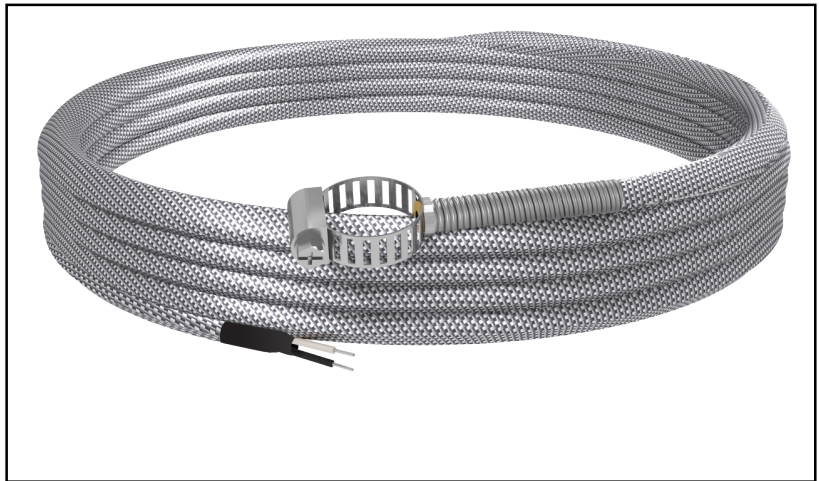

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Standard Bayonet "J" Type Thermocouples Temperature Sensor

Diameter(M): 19 x 26mm

Cable Length(K): 3m

Applications Fields

- Machinery Manufacturing
- Panel Manufacturing
- Production and Test Equipment
- Food, Chemical, Textile Sectors
- Industrial Control Applications


General Specifications

Max. Operating Temperature	-50 °C / +400 °C
Standard cable types	Fiber glass + fiber glass + braided wire
Sensor type	"J" Type Thermocouples FeCu-Ni (DIN/IEC-584)
Mounting	Screw clamp and spring

Mechanical Specifications

Diameter (M)	19 x 26mm
Cable Length (K)	3m

Electrical Connection

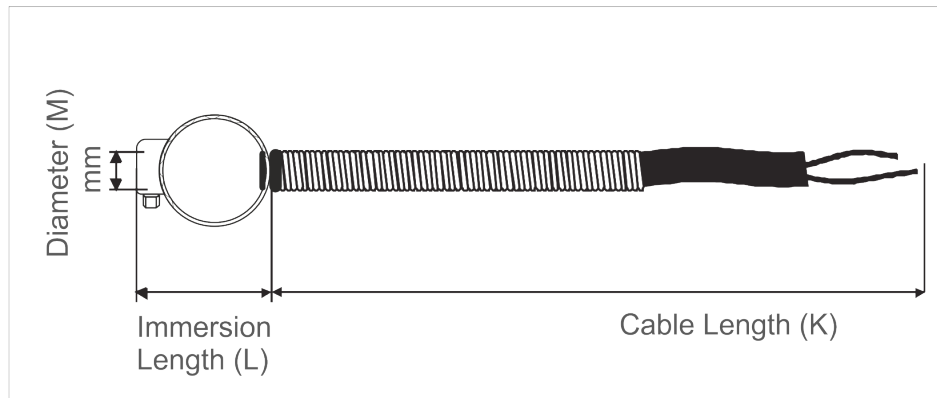

Thermoelement Connections

