

recommended extras

Smart Wireless Headset pro
Pure listening pleasure



Sony USB portable
power supply

Charge your
smartphone on the go



SmartWatch
Your window to your world



made to store more

Now there's 50GB of free storage for your music, videos, photos and more – and you can use it forever. Together with Box® we are offering you a place to store all your stuff that can be accessed at any time from your phone, computer or tablet. Just download the Box for Android app to set up an account from your Xperia™ go to claim your free storage space**.

**This is a time limited offer that ends 31 December 2012.

on the web

Come visit us online! Music, games, extended user guide, phone software, computer programs and much more. All in one place.

Everything worth knowing about your phone:
www.sonymobile.com/xperia-go



Join us on [facebook.com/sonymobilesg](https://www.facebook.com/sonymobilesg) for more exciting updates!



FREE ADDITIONAL 3 MONTHS WARRANTY! Simply register within 14 days of your purchase at sonymobile.ewarranty.sg

Facts and features may vary depending on local variant. Operational times are affected by network preferences, type of SIM card, connected accessories and various activities e.g. playing games. Kit contents and colour options may differ from market to market. The full range of accessories may not be available in every market.

© Sony Mobile Communications AB

Sony "make.believe" and Bravia are trademarks or registered trademarks of Sony Corporation. Xperia is a trademark or registered trademark of Sony Mobile Communications AB. Android™ and YouTube™ are trademarks of Google Inc. All other trademarks or registered trademarks are property of their respective owners.

Sony Mobile Communications AB, SE-221 88 Lund, Sweden. Printed in July 2012.

Xperia™ go specifications

Colours	Black • White • Yellow
Facts	Size: 111 x 60.3 x 9.8 mm • Weight: 110 grams Operating system: Google™ Android™ 2.3 (Gingerbread), upgradeable to Android 4.0 (Ice Cream Sandwich) Processor: 1 GHz NovaThor™ U8500 Dual-core Cortex A9
Camera	3D Sweep panorama™ • 5 megapixel camera 16x digital zoom • 16x video zoom HD video recording (720p) • LED photo flash
Music	3D surround sound xLOUD™ Experience
Internet	Google Play™ (Google Play includes Android Market, Google Music and the Google eBookstore) Google™ search Google Voice™ Search
Entertainment	FigureRunning™ • miCoach™ app Walk Mate
Connectivity	3.5 mm audio jack (CTIA) Bluetooth™ wireless technology DLNA Certified® USB High speed 2.0 support Wi-Fi®
Display	3.5" Reality Display with Mobile BRAVIA® Engine 480x320 pixels • 16,777,216 colour TFT Anti-reflection coating on scratch-resistant mineral glass
Memory	8 GB (up to 4 GB user-accessible memory) RAM: 512 MB • Flash memory: 8GB eMMC microSD™, up to 32 GB
Networks	ST271 UMTS HSPA 900 (Band VIII), 2100 (Band I) GSM GPRS/EDGE 850, 900, 1800, 1900
Battery life	Talk time GSM: Up to 6 hours and 30 minutes** Standby time GSM: Up to 500 hours** Talk time UMTS: Up to 5 hours and 30 minutes** Standby time UMTS: Up to 500 hours** Music listening time: Up to 45 hours Video playback time: Up to 7 hours Embedded battery: 1305 mAh (built-in), typical 1265 mAh, minimum **Values are according to GSM Association Battery Life Measurement Technique. Battery performance may vary depending on network conditions and configurations, and phone usage.
In the kit	Xperia™ go • Built-in battery Stereo headset • Charger Micro USB cable for charging, synchronisation and file transfer User documentation Sim card adaptor

All services mentioned in this leaflet may not be available in every market.

*IP67, according to International Protection Rating. IP67 implies that when the phone is correctly mounted to maintain its dust and water resistant qualities, there is no ingress of dust (digit 6) and that ingress of water (digit 7) in harmful quantity shall not be possible if the device is dropped in fresh water under up to 1 m of submersion for a duration of maximum 30 minutes.

Despite your device's resistance qualities, you should avoid exposing it to environments with excessive dust or moisture. Damage to your device, (even if through ordinary use) can limit or lessen resistance to dust or moisture.



SONY
make.believe




made to resist

Xperia™ go
The stylish Sony smartphone
made for extra durability

XPERIA

the new Xperia™ go

Sleek, stylish and extra durable, the Xperia™ go is always ready to entertain you. Enjoy millions of songs and all your favourite films. Shoot shots fast, or film your friends in razor-sharp HD. Busy cooking? Walking in the rain? Relaxing on the beach? Use Xperia™ go, even when your fingers are wet. Then share everything instantly, or show it all on your TV at home. Stylish just got incredibly strong.

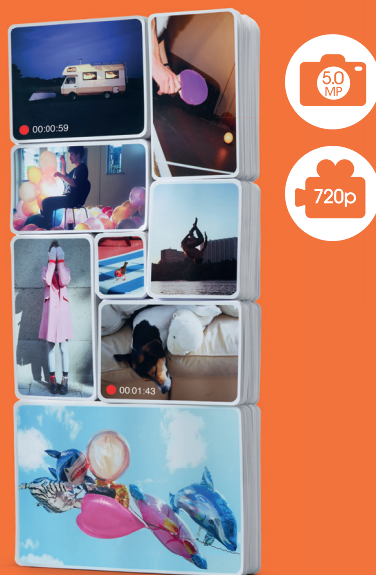

made to share

Seen some action? Grab it quick with the super-fast 5 megapixel camera - from sleep to snap in just over a second. Or bring it to life in razor-sharp high definition video. Finished shooting? Post everything on your favourite social site, or share it on your TV using DLNA®.

made to watch

Big audience? Treat them to a show on the big screen, or make your music scream out loud. Xperia™ go is DLNA® enabled, so you can share all your stills, videos, web links and music with any DLNA enabled device via Wi-Fi®, like a BRAVIA® HDTV, home theatre system, Sony Tablet or Vaio® laptop.



made to outperform

Get the best out of your entertainment on the razor sharp 3.5" Reality Display with Mobile BRAVIA® Engine. With the dual core 1 GHz processor you can browse, stream and download what you like in an instant - all on a slick smartphone that's just 9.8 mm thin - and play it directly through your BRAVIA® TV or sound system.



made to resist

With the highest level of dust and water resistance available on any smartphone, Xperia™ go is designed to take whatever life throws at it. Getting soaked outside? Use GPS Navigation to find that restaurant on the scratch resistant display, then call a taxi, even with wet fingers. Into sports? Compete and share your exercise stats with the miCoach™ app, or get fit and artistic with FigureRunning™.

