

compact Pin Busbar, 10mm² connection: 3p/N compact device 1-pole touch protected 1000mm cuttable



Versie	
productmerksnaam	SETRON
Algemene technische gegevens	
aantal fasen	3
Elektriciteit	
continustroom / nominale waarde	63 A
Hoofd-circuit	
bedrijfsspanning / nominale waarde / maximaal	230 V
Geschiktheid	
geschiktheid voor samenwerking	
• apparaten met hulpschakelaar	Geen
• apparaten met nulgeleider	Ja
Product Details	
producteigenschap / elektrisch geïsoleerd	Ja
Aantal	
aantal apparaten / geschikt voor aanbouw	60

Aansluitingen

uitvoering van de elektrische aansluiting	Stift
---	-------

Mechanical Design

verdelingsmaat	1 mm
hoogte	13 mm
lengte	1 060 mm
nettogewicht	679 g

Certificaten

Declaration of Conformity



EG-Konf.

Verdere informatie

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/nl/nl/Catalog/product?mlfb=5ST3773-0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/nl/ps/5ST3773-0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3773-0

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

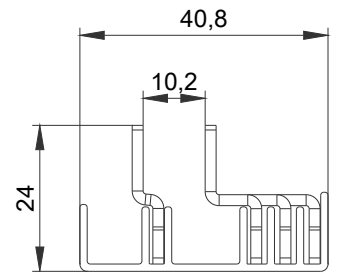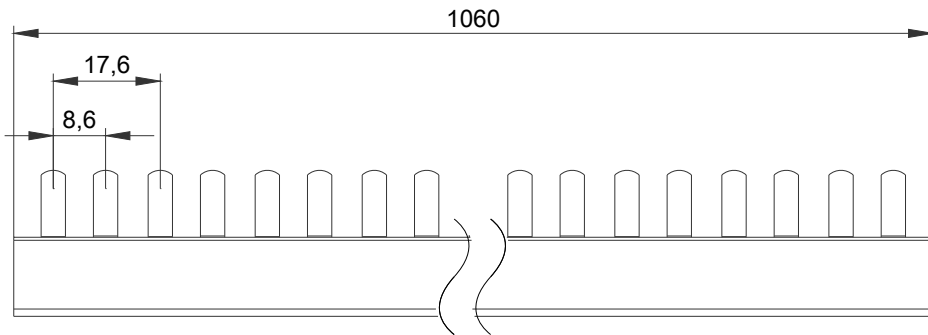

5ST3773-0

