




Lampholder with flange

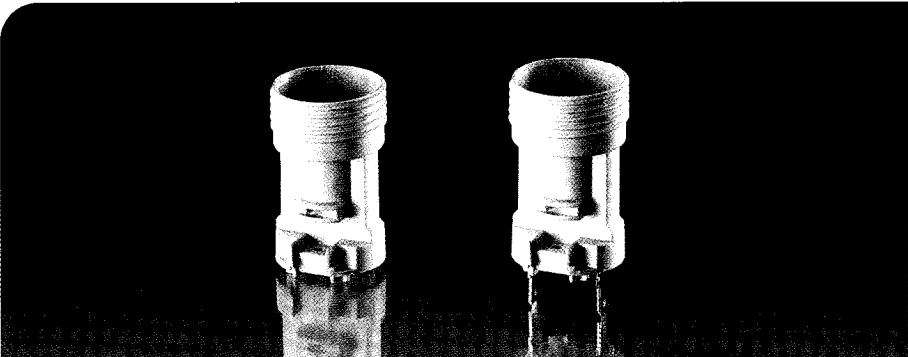

T180
T190
T210

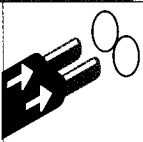

0.5 - 1.5 mm²

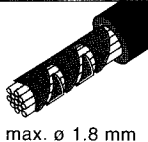


max. ø 1.8 mm





0.5 - 1.5 mm²



413 - 416

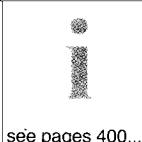

see pages 400...

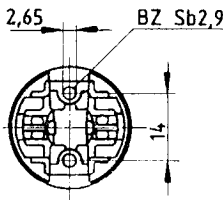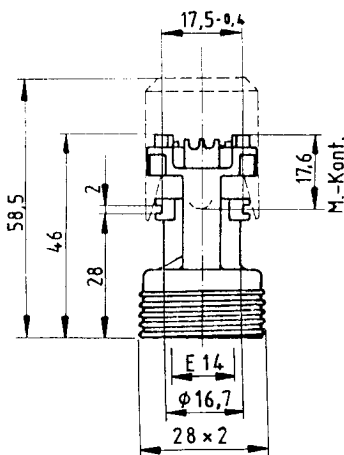

**Snap in, push in
or screw fixing**

pkg. wt. part no.

for self-tapping screws BZ Sb
2,9 DIN 7971 with location
groove DIN 78

T 180



white 500 10g **22.225.3306.50**
black 500 10g **22.225.3306.80**

T 190

white 500 10g **22.225.3706.50**
black 500 10g **22.225.3706.80**

T 210

natural colour 500 11g **22.225.3906.51**

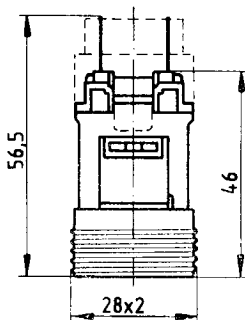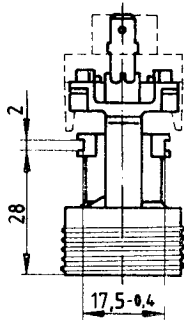

Snap in or push in fixing
lampholders with tab
terminals 4.8 x 0.8 mm

T 180

white 500 12g **22.225.3316.50**

T 190

white 500 12g **22.225.3716.50**
black 500 12g **22.225.3716.80**

T 210

natural colour 500 13g **22.225.3916.51**

can be combined with insulating cap 22.934 see page 414

