


LED MR16 ALL-GLASS DIMMERABILE

SLD670642D

5,0 W - 470lm - 3000K

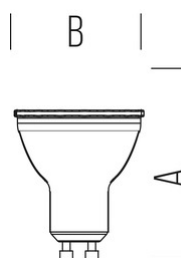

DIMENSIONS	A	B	C
1	45	---	50

GENERAL INFORMATIONS	
Code	SLD670642D
Ean	8031453021405
Family	LED MR16 ALL-GLASS DIMMERABILE
Technology	LED
Energy class	A+
Operating temperature (° C)	-20 - +40

PACKAGING	
Packaging	BOX
Pack	10 / 50

LIGHTING DATA	
Kelvin (°)	3000
Lumen	470
Useful Lumen (lm)	360
Candela (cd)	510
Beam (°)	60
Luminous efficacy (lm / W)	94
Color rendering (CRI)	>80

TECHNICAL FEATURES	
Base	GU5.3
Power (W)	5,0
Equivalence (W)	36
Supply voltage (V) / Max (V)	12 / 12
Power frequency (Hz)	50/60
Power factor	>0,50
Dimmer compatibility	SI