

MICON 5, square plunger 14.5 mm, mechanical stop limit, yellow, GH 9.55 mm



fields of application

> Measurement-control-regulation

> Mechanical and system engineering

> Automotive

> Signalling systems

> Vehicle construction

> Handheld terminals

description

The wide selection of standard plungers in different shapes and colors guarantees a versatile range of applications for the MICON 5 tactile switch.

technical data

> general


Bezel color	yellow	direct links
illuminated	Yes	> RAFI eCatalog
Packaging unit	100 pcs.	
net weight	0.9 g	
MOQ order	100 pcs.	
RoHS compliant	Yes	
REACH compliant	Yes	

> mounting diameters

Outside dimension, length	8.7 mm
Outside dimension, width	14.5 mm
Outside dimension, height	14.5 mm
Plunger length L	6.2 mm
Support height A	3.35 mm
Total height GH	9.55 mm


drawings

Dimensioned drawing

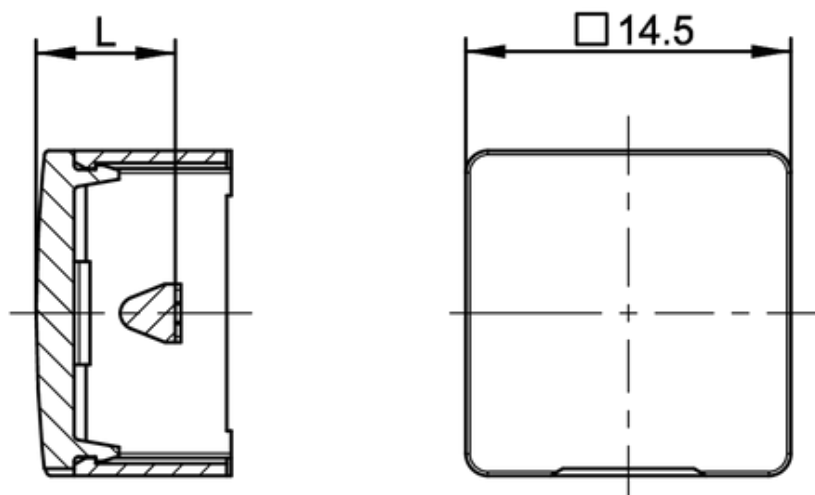

System drawing

Structure:
High embossing 0.35 mm
Adhesive thickness 0.15 mm

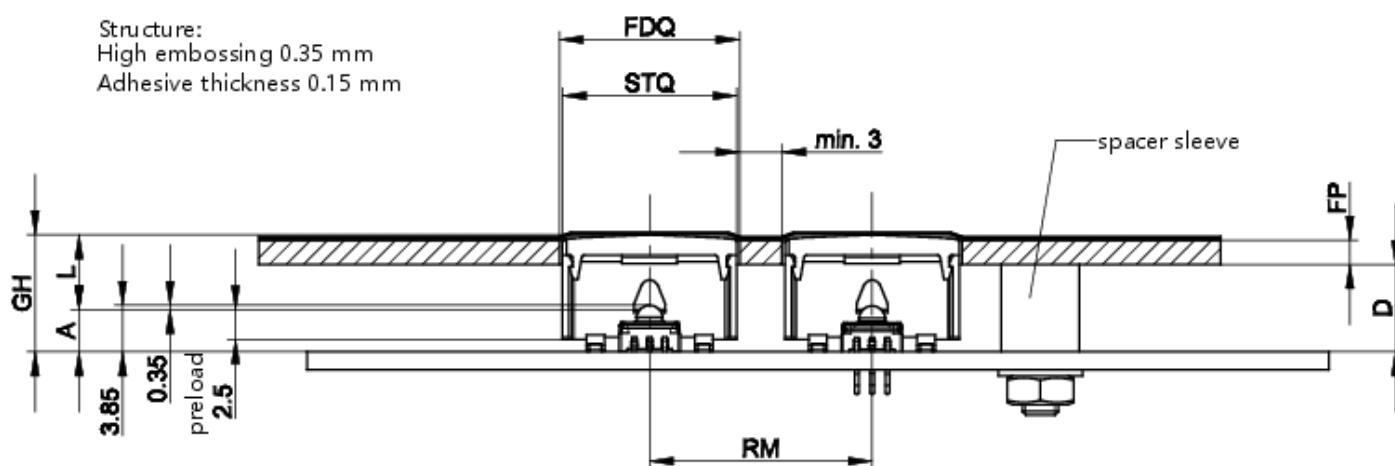

$$GH=A+L$$

PCB drawing

View without front panel,
foil and screen

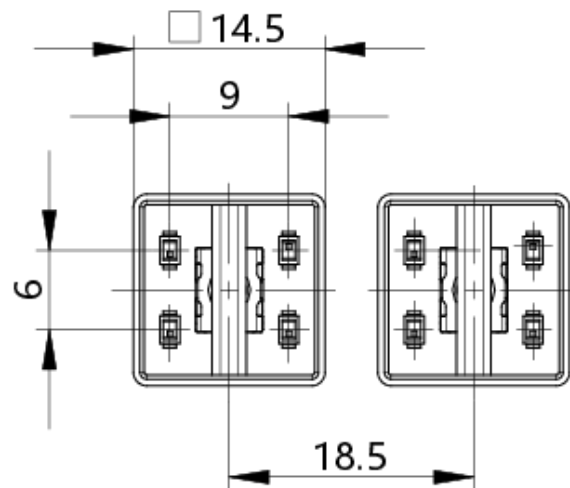


Illustration with 4 LED OSRAM LO M676-Q1R1-24

PCB drawing

View without front panel,
foil and screen

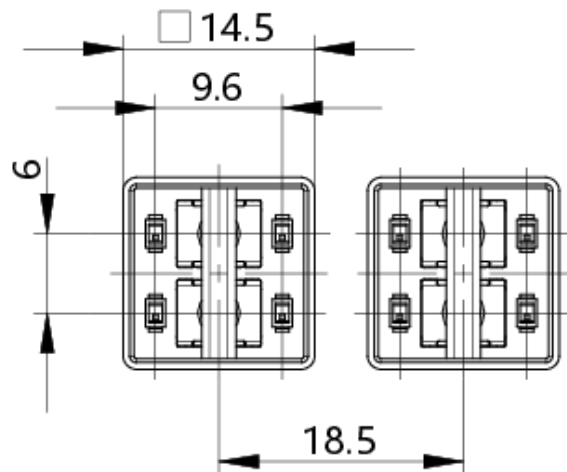


Illustration with 4 LED OSRAM LO M676-Q1R1-24