

Features

- Crocodile Clips
- Lug connection
- Jaw open 1.81" (46 mm) max
- Material: Copper
- Length: 7.75" (196.8 mm)
- Rating: 300 Amps

RS PRO Crocodile Clips, Copper Contact, 300A

RS Stock No.: 0205388



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Crocodile Clips



Product Description

- Widely used as a welding ground clamp
- This heavy-duty grounding alligator clips are suitable for use in applications that required a strong hard wearing high amperage alligator clip such as welding equipment, high power generators, battery charge packs and many other applications.
- This Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips
- A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip

General Specifications

Material	Copper
Product Name	Crocodile Clips
Type	Welding Clip
Colour	Copper
Insulated	No
Connection Type	Lug connection

Commented [波辛1]:

Electrical Specifications

Current rating	300A
----------------	------

Mechanical Specifications

Jaw Opening ($\pm 10\%$)	1.81" (46 mm) max
Contact Material	Copper
Insulation Material	No
Dimensions ($\pm 10\%$)	Overall length 7,75"(196.8mm), overall height 2.5" (63.5mm)


Approvals

Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

Spec Drawings Diameter

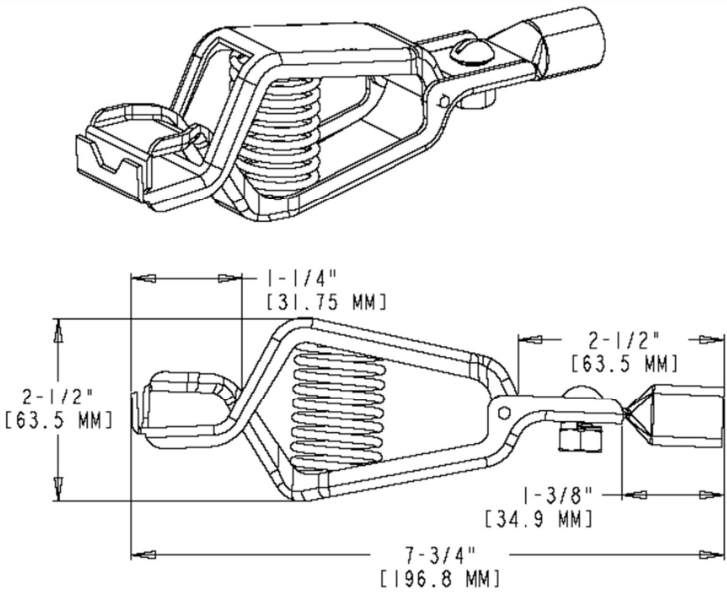

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION