
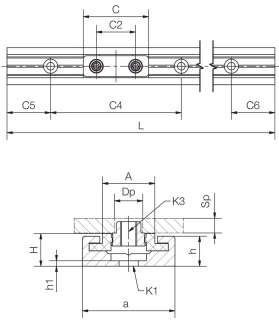


drylin® N guide carriage installation size 17
iglidur® J sliding element
NW-02-17

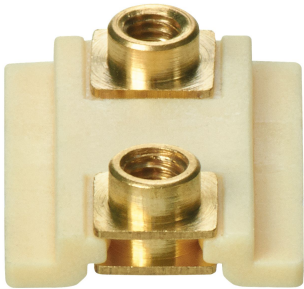

drylin® N guide carriage installation size 17
iglidur® J sliding element

- Material sliding element: iglide® J
- Mounting type: Threaded bosses
- Installation size: 17
- Load capacity, stat.: 11 lbs (50 N))

Product description

Introducing the drylin N guide carriage, installation size 17, featuring an iglidur J sliding element. This innovative carriage is designed for easy mounting with threaded bosses, ensuring a secure fit. With a static load capacity of 11 lbs (50 N), it offers reliable performance for your projects. Ideal for those seeking durability and efficiency, the drylin N guide carriage is the perfect choice for your guiding needs.

Manufacturing and installation tolerances

H-tolerance	±0,35 mm
-------------	----------

Mechanical properties

Static load capacity	50 N
----------------------	------

Dimensions

A	9.6 mm
C	20 mm
C2	14 mm
Sp	2.5 mm
Dp	5 mm
Thread K3	M3



General properties

Sliding element material	iglidur® J
Floating bearing	none
Type of fastening	Threaded pin
High temperature	No

Certificates and standards

